


1748-UL
Nylon cable ties, for heavy loads, black UV and IMPACT resistant
CE

Material: polyamide PA 6.6 + carbon black
Self-extinguishing class: UL 94-V2
Working temperature: -40 °C ÷ +85 °C
Minimum installation temperature: -10 °C
Resistance to chemicals: Good resistance to bases, oils, greases, chloride solvents. Limited resistance to acids. Not resistant to phenols
Reference standards: EN 62275:2015-02
Classification: type 1 (EN); type 21 (UL)

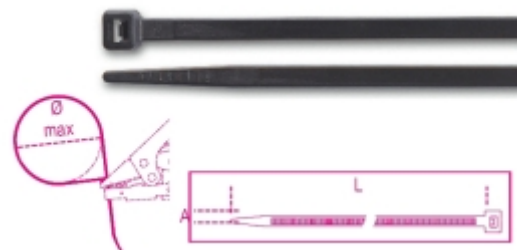

Please indicate number of cable ties, and not of packages, in your order

	art.	A mm	L mm	Ø MAX mm	F MAX N
					
BMN2412	BMN2412	12.4	230	57	1200
BMN4912	BMN4912	12.4	480	136.5	1200
BMN7412	BMN7412	12.4	730	216.1	1200
BMN8912	BMN8912	12.4	880	263.9	1200
BMN1012	BMN1012	12.4	1000	305	1200