

Wall mounted socket  
Part no. 7247




- screw terminals
- switched
- mechanical DUO-interlock
- RCD (0.03A)
- other leakage current ratings on request
- sockets can be padlocked

Technical specifications

|                       |                 |
|-----------------------|-----------------|
| Ampere                | 16 A            |
| Poles                 | 5 p             |
| Voltage               | 400 V           |
| Clock position        | 6 h             |
| Hertz                 | 50-60 Hz        |
| Connection technology | Screw terminals |
| Contact               | standard        |
| Protection type       | IP67            |
| Enclosure material    | Plastic         |
| Weight                | 2353 g          |

Drawing

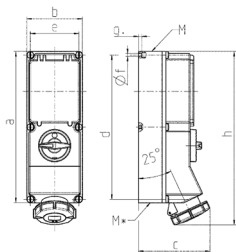

| Drawing<br>1 MB 181/620                            | Amp.<br>Poles | 16    |       |       | 32    |       | 63   |      |
|----------------------------------------------------|---------------|-------|-------|-------|-------|-------|------|------|
|                                                    |               | 3     | 4     | 5     | 4     | 5     | 4    | 5    |
| Dim. in mm                                         | a             | 364   | 364   | 364   | 364   | 364   | 460  | 460  |
|                                                    | b             | 134   | 134   | 134   | 134   | 134   | 180  | 180  |
|                                                    | c             | 160   | 162   | 163   | 168   | 168   | 202  | 202  |
|                                                    | d             | 347   | 347   | 347   | 347   | 347   | 440  | 440  |
|                                                    | e             | 117   | 117   | 117   | 117   | 117   | 160  | 160  |
|                                                    | f             | 6.3   | 6.3   | 6.3   | 6.3   | 6.3   | 8.1  | 8.1  |
|                                                    | g             | 8     | 8     | 8     | 8     | 8     | 8    | 8    |
|                                                    | h             | 391   | 395   | 398   | 408   | 411   | 505  | 505  |
|                                                    | M             | 32/40 | 32/40 | 32/40 | 32/40 | 32/40 | 40   | 40   |
|                                                    | M*            | 2x32  | 2x32  | 2x32  | 2x32  | 2x32  | 2x40 | 2x40 |
| Max. cable diam. (mm)                              |               | 27    | 27    | 27    | 27    | 27    | 27   | 27   |
| Terminal for cond. cross<br>section (mm²) min-max. |               | 1.5   | 1.5   | 1.5   | 2.5   | 2.5   | 6    | 6    |
|                                                    |               | —4    | —4    | —4    | —10   | —10   | —25  | —25  |