


Self-aligning ball bearings, cylindrical and tapered bore

Principal dimensions			Basic load ratings		Fatigue	Speed ratings		Mass	Designation
d	D	B	C	C_0	load limit P_u	Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
20	47	18	12,7	3,4	0,18	-	10000	0,14	2204 E-2RS1TN9

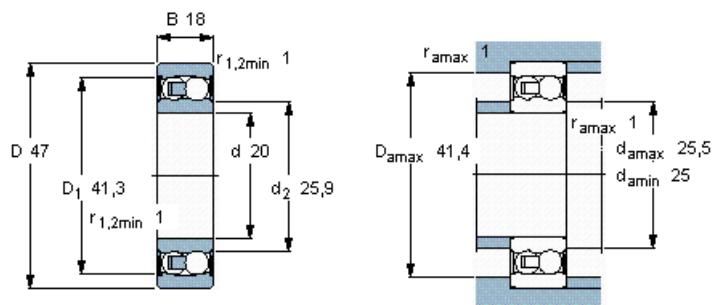

Calculation factors

e 0,3
 Y_1 2,1
 Y_2 3,3
 Y_0 2,2