

Datasheet

## RS Pro 9 mm Orange Neon Indicator Lamp, E10, 220/250 V 1.8 mA

RS Stock No: **655-9441**



### Product Details

RS Pro 9 mm neon indicator lamp in orange colour, operates on 220/250 V ac voltage and 1.8 mA current. This E10 base lamp comes with an average life of 50000 hours. It is suitable for top and side viewing.

### Features and Benefits

- Designed for top and side viewing
- Length 30 mm
- Average life of 50000 hours



**Specifications:**


Current Rating	1.8 mA
Lamp Base	E10
Lamp Size	T10
Length	30 mm
Life Hours	50000 h
Light Colour	Orange
Voltage Rating	220 V, 250 V
Diameter	10 mm

SPECIFICATION SHEET

RS Stock No.

6559441

DRAWING - I

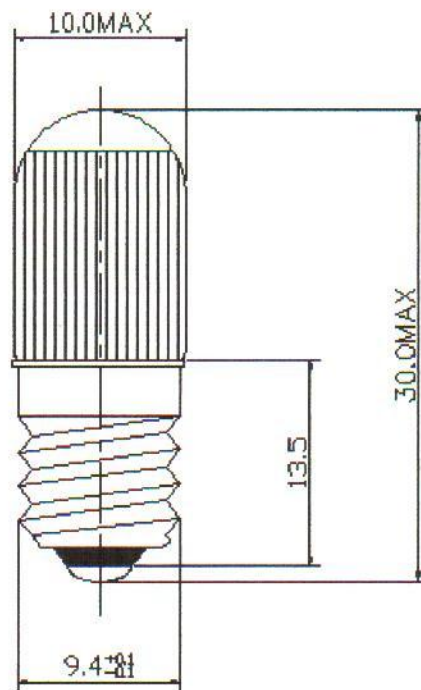

Unit : mm

1. Structure	Bulb Type	T10X30
	Bulb Diameter	Ø10.0Max.
	Length	30.0Max
	Base Type	E10.
2. Design Characteristics	Voltage	220/250V
	Amperage	1.8mA±10%
	Brightness Level	High
	Gas Type	Neon gas-filled
	Life Hours	50,000Hrs