

HC-EVO-B10-SHWSC-2SSM32-PLRBK - Housing



1407637

<https://www.phoenixcontact.com/in/products/1407637>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Surface mounting housing B10, with single locking latch, material: PA 6.6-FR, protective cover material: PC, cable outlets: 2, lateral, 2x M32, height: 74 mm, cable gland: none, protective cover: yes, Standard

Product description

One screw connection opening is closed, however can be opened using a screwdriver

Your advantages

- Lower costs than metal version
- Low weight
- Lower risk of condensation

Commercial data

Item number	1407637
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BF7
Product key	AF7APL
Catalog page	Page 604 (C-2-2019)
GTIN	4046356776998
Weight per piece (including packing)	178.4 g
Weight per piece (excluding packing)	177.8 g
Customs tariff number	85389099
Country of origin	PL

Technical data


Notes

General	For contact inserts HC-B10, BB18, DD42, M, K8/24, HV03-I-PT, HC- 3-E...C
---------	--

Product properties

Product type	Housing with locking latch
Housing type	Surface mounting housing
Product family	HC-EVO-B
Application	Standard
Type	B10
No. of cable outlets	2
Type of the screw connection	2x M32
Type	Tall design
Protective cover	yes
Cable outlet	lateral
Pg screw connection	none

Dimensions

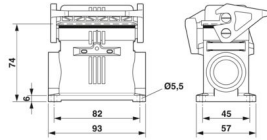Dimensional drawing	
Width	57 mm
Height	74 mm
Length	93 mm
Hole diameter	5.5 mm

Material specifications

Flammability rating according to UL 94	V0 (Housing)
	V0 (Interlock)
	V0 (Protective cover)
Seal material	NBR
Housing material	PA 6.6-FR
Material, protective cover	PC
Locking latch material	PA

Mechanical properties

Mechanical data	
Type of the screw connection	2x M32
Locking type	Latch

Connection data

Tightening torque	2 Nm ... 3 Nm (for M5 mounting screws on the surface-mount housing)
-------------------	---

Mounting

Assembly note	One of the two openings for the screw connections is sealed but can be broken open using a screwdriver.
---------------	---


Environmental and real-life conditions

Ambient conditions

Degree of protection	IP66 (when plugged in or with locked protective cover)
Enclosure rating (NEMA)	12 (UL 50e)
Impact strength	IK08
Ambient temperature (operation)	-40 °C ... 125 °C

Drawings

Dimensional drawing

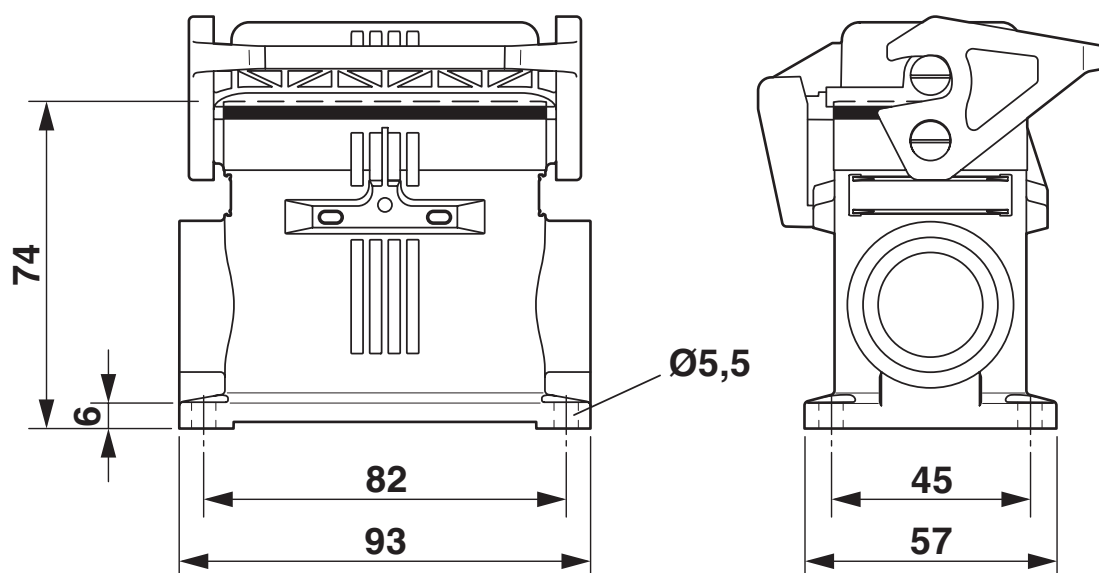

Dimensional drawing

HC-EVO-B10-SHWSC-2SSM32-PLRBK - Housing



1407637

<https://www.phoenixcontact.com/in/products/1407637>

Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/in/products/1407637>

DNV

Approval ID: TAE000037S



EAC

Approval ID: RU C-DE.AI30.B.01102

HC-EVO-B10-SHWSC-2SSM32-PLRBK - Housing



1407637

<https://www.phoenixcontact.com/in/products/1407637>

Classifications

ECLASS

ECLASS-11.0	27440202
ECLASS-12.0	27440202
ECLASS-13.0	27440202

ETIM

ETIM 9.0	EC000437
----------	----------

UNSPSC

UNSPSC 21.0	31261500
-------------	----------

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

HC-EVO-B10-SHWSC-2SSM32-PLRBK - Housing



1407637

<https://www.phoenixcontact.com/in/products/1407637>

Accessories

G-INS-M32-M68N-PNES-BK - Cable gland

1411136

<https://www.phoenixcontact.com/in/products/1411136>



Cable gland, material for screw connection: PA, application: Standard, external cable diameter 15 mm ... 21 mm, shielding: no, connecting thread: M32 x 1.5, color: jet black RAL 9005

HC-B10-SP-RBK - Profile gasket

1407707

<https://www.phoenixcontact.com/in/products/1407707>



Profile gasket for HEAVYCON EVO supporting base element type B10

HC-EVO-B10-SHWSC-2SSM32-PLRBK - Housing



1407637

<https://www.phoenixcontact.com/in/products/1407637>

HC-B10-SL-PLBK - Housing brackets

1407698

<https://www.phoenixcontact.com/in/products/1407698>



Replacement single locking latch for HEAVYCON EVO housing type B10, PA

HC-B10-BC-HI-PLBK - Protective cover

1407693

<https://www.phoenixcontact.com/in/products/1407693>



Protective cover B10, for single locking latch, protective cover material: PC, height: 19.1 mm, seal: no

HC-EVO-B10-SHWSC-2SSM32-PLRBK - Housing



1407637

<https://www.phoenixcontact.com/in/products/1407637>

REDUC-K-KV-M32/M25 BK - Reducing adapter

1410712

<https://www.phoenixcontact.com/in/products/1410712>



Reducing adapter, connecting thread: M32 x 1.5, color: jet black, with flat gasket

REDUC-K-KV-M32/M20 BK - Reducing adapter

1410725

<https://www.phoenixcontact.com/in/products/1410725>



Reducing adapter, connecting thread: M32 x 1.5, color: jet black, with flat gasket

HC-EVO-B10-SHWSC-2SSM32-PLRBK - Housing



1407637

<https://www.phoenixcontact.com/in/products/1407637>

US-EMP (20X9) - Snap-in markers

0829439

<https://www.phoenixcontact.com/in/products/0829439>



Snap-in markers, Card, white, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: latching, Number of individual labels: 70, text field height: 9 mm, text field width: 20 mm

US-EMP (20X9) CUS - Snap-in markers

0830028

<https://www.phoenixcontact.com/in/products/0830028>



Snap-in markers, Card, can be ordered: by card, white, labeled according to customer specifications, mounting type: snapped into marker carrier, Number of individual labels: 70, text field height: 9 mm, text field width: 20 mm

HC-EVO-B10-SHWSC-2SSM32-PLRBK - Housing

1407637

<https://www.phoenixcontact.com/in/products/1407637>



HC-STA-B10-DC-PL - Protective cover

1421101

<https://www.phoenixcontact.com/in/products/1421101>

Protective cover, design: B10



A-INSP-M32-65N-P-BK - Screw plug

1415208

<https://www.phoenixcontact.com/in/products/1415208>

Screw plug, material for screw connection: PA, connecting thread: M32 x 1.5, color: jet black RAL 9005, with O-ring



Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.
A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420
info@phoenixcontact.co.in