

# Block assembly kit, Series AS5-MBR-...-W05

2024-08-13

R412009367

## Series AS5


Qn = 14500 l/min



## Technical data

|                          |                                |
|--------------------------|--------------------------------|
| Industry                 | Industrial                     |
| Port                     | G 1                            |
| Min. ambient temperature | -10 °C                         |
| Max. ambient temperature | 50 °C                          |
| Weight                   | 0.68 kg                        |
| Housing material         | Die cast zinc                  |
| Surface housing          | painted                        |
| Seal material            | Acrylonitrile butadiene rubber |
|                          | R412009367                     |

## Dimensions

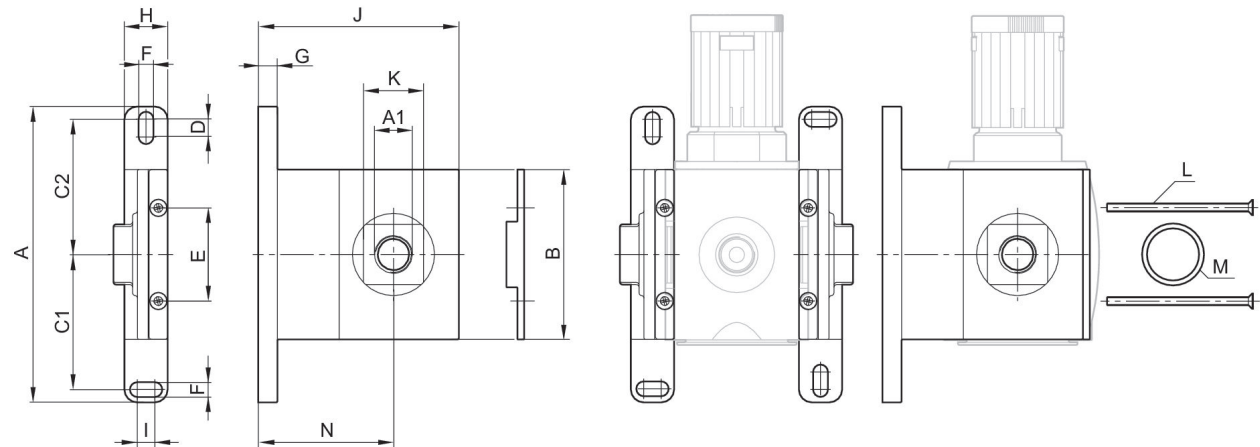

# Block assembly kit, Series AS5-MBR-...-W05

2024-08-13

R412009367

| Part No.   | A1    | A   | B   | C1   | C2   | D  | E  | F   | G  |
|------------|-------|-----|-----|------|------|----|----|-----|----|
| R412009366 | G 3/4 | 160 | 102 | 72.5 | 72.5 | 10 | 57 | 8.4 | 10 |
| R412009367 | G 1   | 160 | 102 | 72.5 | 72.5 | 10 | 57 | 8.4 | 10 |

| Part No.   | H  | I  | J   | K  | L     | M      | N  |
|------------|----|----|-----|----|-------|--------|----|
| R412009366 | 30 | 10 | 127 | 41 | M6x90 | 37x2,3 | 87 |
| R412009367 | 30 | 10 | 127 | 41 | M6x90 | 37x2,3 | 87 |