
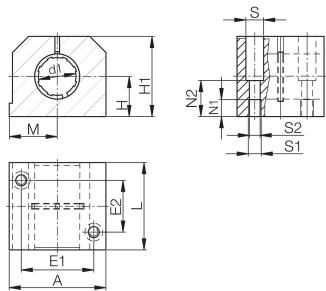


drylin® R pillow block RJUM-06

RJUM-06-25

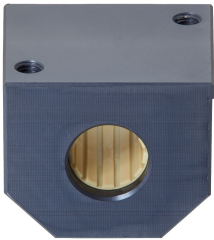

drylin® R pillow block RJUM-06

Part number	RJUM-06-25
Ø d1	25 mm
H1	60 mm
A	78 mm
M	39 mm
E1	60 mm
E2	40 mm
Ø S	15 mm
S1	M10
Ø S2	8.4 mm
N1	29 mm
N2	22 mm
H Bolt	30 mm

Product description

Introducing the drylin R pillow block RJUM-06, a reliable solution for your bearing needs. This product features a durable design, ensuring long-lasting performance. Ideal for various applications, it offers a matching replacement liner for easy maintenance. Trust the drylin brand for quality and efficiency in your projects. Choose the RJUM-06 for a dependable and effective bearing solution.

Dimensions

Ø d1	25 mm
H Bolt	30 mm
H1	60 mm
S1	M10
M	39 mm
E1	60 mm
E2	40 mm
A	78 mm
Ø S	15 mm
L	67 mm



General properties

Sliding element material

iglidur® J

Housing material

anodised aluminium

Certificates and standards



Additional information and diagrams

