

FOC-SB-FR19:1U-LCD24-OS2 BK - Splice box



1080812

<https://www.phoenixcontact.com/in/products/1080812>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Splice box, design: 1RU, degree of protection: IP20, material: Metal, connection method: Splicing, color: black, Ethernet



Product description

19" FDX 20 series splice boxes, 1 RU, with removable drawer, for 24x LC duplex OS2, black, completely ready to splice (correctly pre-mounted: 24 couplings, 48 pigtails, 4 cassettes, 4 combs, 1 cassette cover).

Your advantages

- Intuitive front-panel operation and clear control cabinet layout thanks to uniform design
- Flexible DIN rail mounting possible in six positioning directions
- Suitable for industrial applications
- Reduced installation time with plug-and-play
- Pin assignment straight in line in a link
- Continuously reliable data connection, thanks to extensively tested components
- Snap-on mounting on standard DIN rails NS 35/7.5 or NS 35/15
- Transmission rate up to 1000 Mbps

Commercial data

Item number	1080812
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	ABN
Product key	ABNGBA
GTIN	4055626805566
Weight per piece (including packing)	2,873.9 g
Weight per piece (excluding packing)	2,873.9 g
Customs tariff number	85367000
Country of origin	DE

FOC-SB-FR19:1U-LCD24-OS2 BK - Splice box



1080812

<https://www.phoenixcontact.com/in/products/1080812>

Technical data

Product properties

Product type	Network distributor box
Housing type	Component housing
Series	FDX 20 series
Type	19" rack patch module
Sensor type	Ethernet
Connection profile	LC-Duplex
No. of cable outlets	4
No. of conductors	48
Number of module slots	24
Number of slots	48
Protective cover	yes

Electrical properties

Attenuation	≤ 0.3 dB
Transmission medium	FO

Connection data

Connection technology	
Connection method	Splicing

Dimensions

Width	483 mm
Height	44.45 mm
Depth	241.5 mm

Mechanical characteristics

Ferrule diameter	1.25 mm
------------------	---------

Material specifications

Color	black
Flammability rating according to UL 94	V0
Ferrule material	Zirconia ceramics
Housing material	Metal
Housing surface material	Powder-coated, black

Cable/line

Cable type	Fiberglass
Cable type	Single wires
Cable structure	semi-loose compact wires (STB)
External cable diameter	6 mm ... 12 mm
Individual wire diameter	900 µm (250/900 µm)

FOC-SB-FR19:1U-LCD24-OS2 BK - Splice box



1080812

<https://www.phoenixcontact.com/in/products/1080812>

Single wire, color	color coded
--------------------	-------------

FO cable

Number of fibers	48
Fiber	GOF
Fiber type	Single mode fiberglass, 9/125 µm
Attenuation	≤ 0.3 dB (at 1310 nm / 1550 nm)
Return Loss	≥ 50 dB (at 1310 nm / 1550 nm)
Transmission medium	FO

Mechanical properties

Mechanical data

Insertion/withdrawal cycles	min. 1000
Smallest bending radius	30 mm

Characteristics

Attenuation	≤ 0.3 dB
-------------	----------

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP20
----------------------	------

Mounting

Mounting type	19" rack mounting
---------------	-------------------

FOC-SB-FR19:1U-LCD24-OS2 BK - Splice box



1080812

<https://www.phoenixcontact.com/in/products/1080812>

Classifications

ECLASS

ECLASS-13.0	19170113
ECLASS-11.0	19170113

ETIM

ETIM 9.0	EC001130
----------	----------

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

FOC-SB-FR19:1U-LCD24-OS2 BK - Splice box



1080812

<https://www.phoenixcontact.com/in/products/1080812>

Mandatory accessories

FOC-SHRINKSPLICE-PROTECT - Shrink splice protection

1019676

<https://www.phoenixcontact.com/in/products/1019676>



Shrink splice protection, design: Straight, degree of protection: IP20, cable outlet: above and below, color: transparent

FOC-CRIMPSPLICE-PROTECT - Crimp splice protection

1019678

<https://www.phoenixcontact.com/in/products/1019678>



Crimp splice protection, design: Straight, degree of protection: IP20, connection method: Crimp connection, cable outlet: above and below, color: Bare metallic

Accessories

FOC-SB-FR19:1U-LCD24-OS2 BK - Splice box

1080812

<https://www.phoenixcontact.com/in/products/1080812>



FOC-LC:PA-LC:PA-OS2:D01/1 - FO patch cable

1115636

<https://www.phoenixcontact.com/in/products/1115636>

Single-mode OS2 duplex jumper, LC-LC, UPC polishing, length 1 m



FOC-LC:PA-ST:PA-OS2:D01/1 - FO patch cable

1115596

<https://www.phoenixcontact.com/in/products/1115596>

Single-mode OS2 duplex jumper, LC-ST, UPC polishing, length 1 m



FOC-SB-FR19:1U-LCD24-OS2 BK - Splice box



1080812


<https://www.phoenixcontact.com/in/products/1080812>

FOC-LC:PA-SC:PA-OS2:D01/1 - FO patch cable

1115618

<https://www.phoenixcontact.com/in/products/1115618>

Single-mode OS2 duplex jumper, LC-SC, UPC polishing, length 1 m

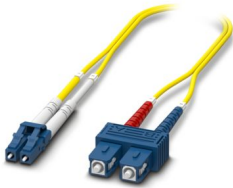

FOC-LC:PA-LC:PA-OS2:D01/2 - FO patch cable

1115629

<https://www.phoenixcontact.com/in/products/1115629>

Single-mode OS2 duplex jumper, LC-LC, UPC polishing, length 2 m



FOC-SB-FR19:1U-LCD24-OS2 BK - Splice box

1080812

<https://www.phoenixcontact.com/in/products/1080812>



FOC-LC:PA-ST:PA-OS2:D01/2 - FO patch cable

1115595

<https://www.phoenixcontact.com/in/products/1115595>

Single-mode OS2 duplex jumper, LC-ST, UPC polishing, length 2 m




FOC-LC:PA-SC:PA-OS2:D01/2 - FO patch cable

1115617

<https://www.phoenixcontact.com/in/products/1115617>

Single-mode OS2 duplex jumper, LC-SC, UPC polishing, length 2 m

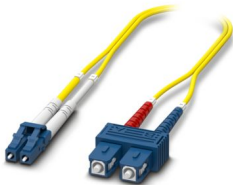

FOC-SB-FR19:1U-LCD24-OS2 BK - Splice box

1080812

<https://www.phoenixcontact.com/in/products/1080812>



FOC-LC:PA-LC:PA-OS2:D01/5 - FO patch cable

1115626

<https://www.phoenixcontact.com/in/products/1115626>

Single-mode OS2 duplex jumper, LC-LC, UPC polishing, length 5 m



FOC-LC:PA-ST:PA-OS2:D01/5 - FO patch cable

1115592

<https://www.phoenixcontact.com/in/products/1115592>

Single-mode OS2 duplex jumper, LC-ST, UPC polishing, length 5 m



FOC-SB-FR19:1U-LCD24-OS2 BK - Splice box

1080812

<https://www.phoenixcontact.com/in/products/1080812>




FOC-LC:PA-SC:PA-OS2:D01/5 - FO patch cable

1115615

<https://www.phoenixcontact.com/in/products/1115615>

Single-mode OS2 duplex jumper, LC-SC, UPC polishing, length 5 m

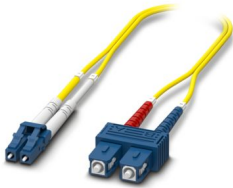

FOC-ADAPTER:LCD/LCD-OSP - Fiber optic coupling

1208073

<https://www.phoenixcontact.com/in/products/1208073>

Fiber optic coupling, degree of protection: IP20, number of positions: 2, material: Plastic, connection method: Coupling, cable outlet: straight, color: blue



FOC-SB-FR19:1U-LCD24-OS2 BK - Splice box



1080812

<https://www.phoenixcontact.com/in/products/1080812>

FOC-ADAPTER:LCD/LCD-OSA - Fiber optic coupling

1208077

<https://www.phoenixcontact.com/in/products/1208077>




Fiber optic coupling, degree of protection: IP20, number of positions: 2, material: Plastic, connection method: Coupling, cable outlet: straight, color: green

FOC-PT9:LC-OSP/2.5 - Fiber optic cable

1208105

<https://www.phoenixcontact.com/in/products/1208105>

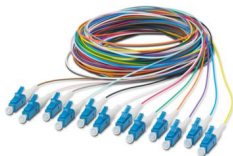

Fiber optic cable, design: LC, degree of protection: IP20, cable length: 2.5 m, number of positions: 12, 100 Gbps, connection method: LC, cable outlet: straight, color: blue

FOC-SB-FR19:1U-LCD24-OS2 BK - Splice box

1080812

<https://www.phoenixcontact.com/in/products/1080812>




FOC-PT9:LC-OSA/2.5 - Fiber optic cable

1208106

<https://www.phoenixcontact.com/in/products/1208106>

Fiber optic cable, design: LC, degree of protection: IP20, cable length: 2.5 m, number of positions: 12, 100 Gbps, connection method: LC, cable outlet: straight, color: green

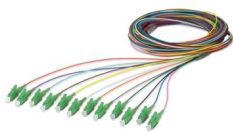

FOC-OE-OE-GL-U-OS2-24/... - FO cable

1286210

<https://www.phoenixcontact.com/in/products/1286210>



GOF universal cable, 24-wire, loose tube cable for fixed installation, non-metallic rodent protection, can be easily stripped, UV-resistant, high mechanical and thermal stability, low smoke, halogen-free and self-extinguishing, improved tread resistance, longitudinally and transversely watertight

FOC-SB-FR19:1U-LCD24-OS2 BK - Splice box

1080812

<https://www.phoenixcontact.com/in/products/1080812>



FOC-OE-OE-GL-U-OS2-12/... - FO cable

1286219

<https://www.phoenixcontact.com/in/products/1286219>



GOF universal cable, 12-wire, loose tube cable for fixed installation, non-metallic rodent protection, can be easily stripped, UV-resistant, high mechanical and thermal stability, low smoke, halogen-free and self-extinguishing, improved tread resistance, longitudinally and transversely watertight

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.

A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420

info@phoenixcontact.co.in