

RS Pro Grey Flexible panel trunking

The flexible wiring duct is manufactured with injection moulding method and is made of flame-protected polypropylene.

 
Properties:

Material:	PP blend, free of halogen, silicon and cadmium		
Operation temperature:	static:	-20°C... +80°C	
	dynamic:	0°C... +50°C	
Processing temperature:	>0°C		
Fire behaviour:	self-extinguishing	UL94	V0
Halogen free	yes		
Dielectric strength:	>30kV/ mm		
UV-resistance:	PP is partly UV-resistant, colour changes in case of UV-exposure cannot be excluded		
Colour:	similar RAL 7030 grey		
Delivery lengths:	500 mm		


Specific Features:

- self-adhesive tape as retaining aid on the bottom


10 x 10



Ø20; Ø30; Ø40

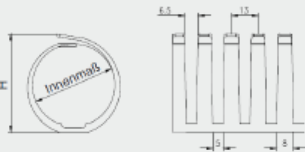

Bodenlochung

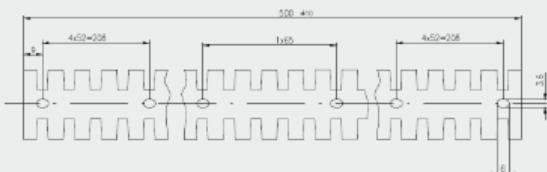

Nominal Size	Height (H)	interior Dimension
10x10	13,5	9,5x9,5
20	24	Ø 20
30	36	Ø 30
40	48	Ø 40