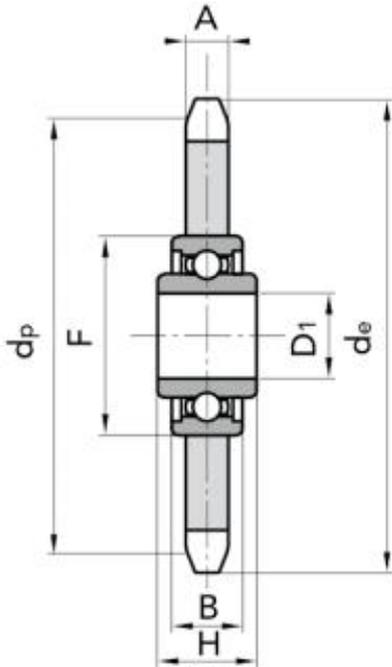
 


30019013

With economic bearing - Idler sprocket

2D Technical Drawing

Dynamic 3D View

Technical Specifications

| | |
|---------------------|--------------|
| Number of teeth (T) | 13 |
| Pitch (P) mm | 3/4" x 7/16" |
| de (DE) mm | 87.5 |
| dp (DP) mm | 79.59 |
| Part number (CODE) | 30019013 |
| A (A) mm | 11.1 |
| D1 (D1) mm | 16 |
| F (F) mm | 40 |
| B (B) mm | 12 |
| H (H) mm | 18.3 |
| Weight (WEIGHT) kg | 0.34 |
| Material (MAT) | STEEL C45 |