



Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 184289-3
RECPT, CONTACT 070, PTPPHBZ



TE Part # 171631-2
070 TAB CONT GOLD



TE Part # 184030-3
RECPT, CONTACT 070, PTPPHBZ



TE Part # 184455-1
ASSY,SSC,2X6 PLUG,C3,KEY A,1-9-11 BLKD




TE Part # 184095-1
RECPT, CONTACT .070, AUPHBZ



TE Part # 184030-1
RECPT, CONTACT 070, AUPHBZ



TE Part # 184141-1
WIRE SEAL,RUBBER,SENSOR,PURPLE, LIM

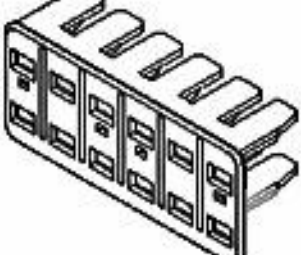

TE Part # 184058-1
12 POS. PLUG DLP




TE Part # 184140-1
WIRE SEAL,RUBBER,SENSOR, ORANGE



TE Part # 184289-1
RECPT, CONTACT 070, AUPHBZ



TE Part # 184373-2
CONTACT, RECEPTACLE, .070 TYPE

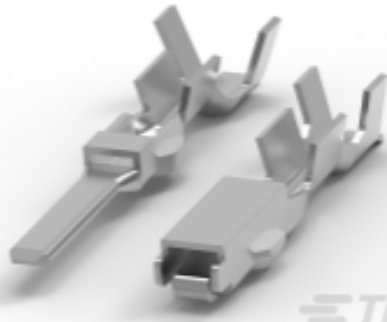

TE Part # CAT-EC7491-T273
Econoseal Receptacles and Tabs



TE Part # 184115-1
12 POS. PLUG ASSY



TE Part # 184139-1
WIRE SEAL,RUBBER,SENSOR,BLUE



TE Part # 184291-1
12 POS. PLUG ASSY



TE Part # 184099-1
12 POS. PLUG ASSY



TE Part # 184095-2
RECPT, CONTACT .070, PTPPHBZ



TE Part # 184373-1
CONTACT, RECEPTACLE, .070 TYPE

Customers Also Bought




TE Part #640919-1
RECEPT,PIDG FASTON 16-14 187



TE Part #1-1456426-5
4POS, MCON 1.2 CB REC 2p TL SEALED



TE Part #CAT-D9934-A75
DYNAMIC 3000 CONTACT

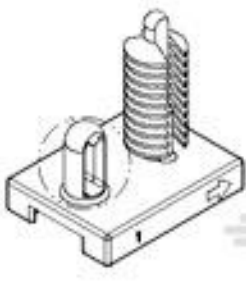

TE Part #1924487-2
MOUNTING CLIP, AMPSEAL 16



TE Part #172233-1
2 POS MINI UMNL CAP HOUSING

TE Part #1-480388-0
03P CMNL PLUG HSG F/H BLK

TE Part #34173
TERMINAL,PG R 12-10 3/8

TE Part #350536-6
UMNL SOK 20-14 .0125AUNI/PHBZ

TE Part #927770-6
JPT REC 2.8 Contact SWS Ag

Documents

Product Drawings

12 POS. PLUG ASSY

English

12 POS. PLUG ASSY

English

CAD Files

3D PDF

English

Customer View Model

ENG_CVM_184097-1_F.2d_dxf.zip

English

Customer View Model

ENG_CVM_184097-1_F.3d_igs.zip

English

Customer View Model

ENG_CVM_184097-1_F.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Application Specification

English