

SETRON, cylindrical fuse holder, 14x51 mm, 3P+N, In: 50 A, Un AC: 690 V



Model	
product brand name	SETRON
product designation	Cylindrical fuse holder
General technical data	
number of poles	4
design of pole	3P+N
size of fuse link	14 x 51 mm
Supply voltage	
operating voltage	690 V
• at AC rated value	
protection class IP	IP20
Mechanical Design	
height	90 mm
width	108 mm
depth	70 mm
net weight	434 g
Certificates	
reference code according to IEC 81346-2	F
Approvals Certificates	
General Product Approval	
Test Certificates	



[Confirmation](#)



[Miscellaneous](#)

other	Environment
Confirmation	Miscellaneous
	Environmental Confirmations

Further information
Information on the packaging
https://support.industry.siemens.com/cs/ww/en/view/109813875
Information- and Downloadcenter (Catalogs, Brochures,...)
http://www.siemens.com/lowvoltage/catalogs
Industry Mall (Online ordering system)
https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NW7161
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3NW7161>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NW7161


CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

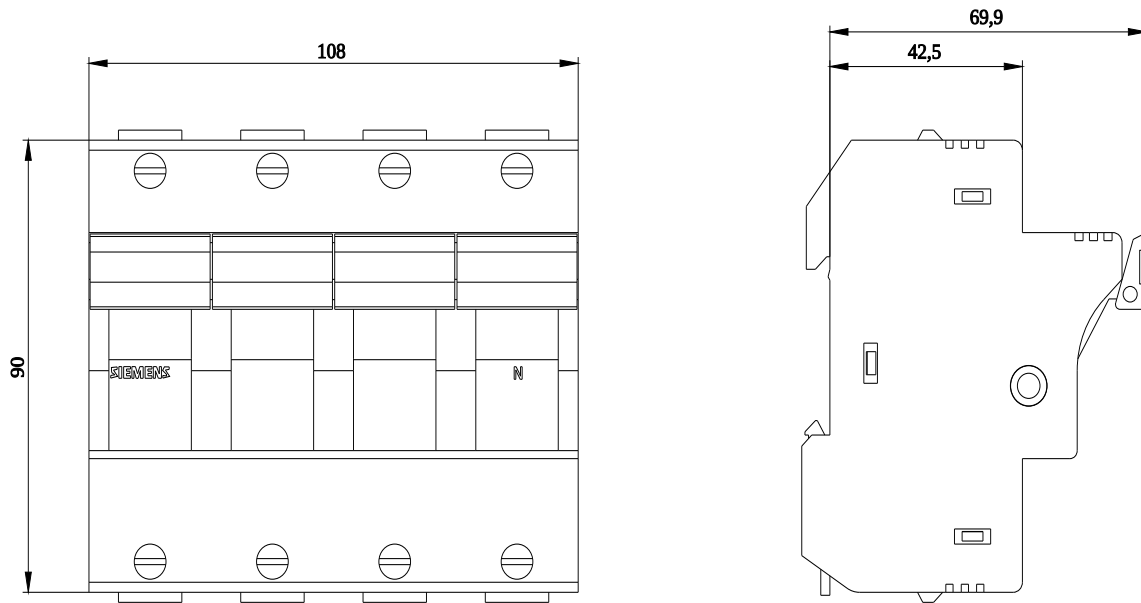

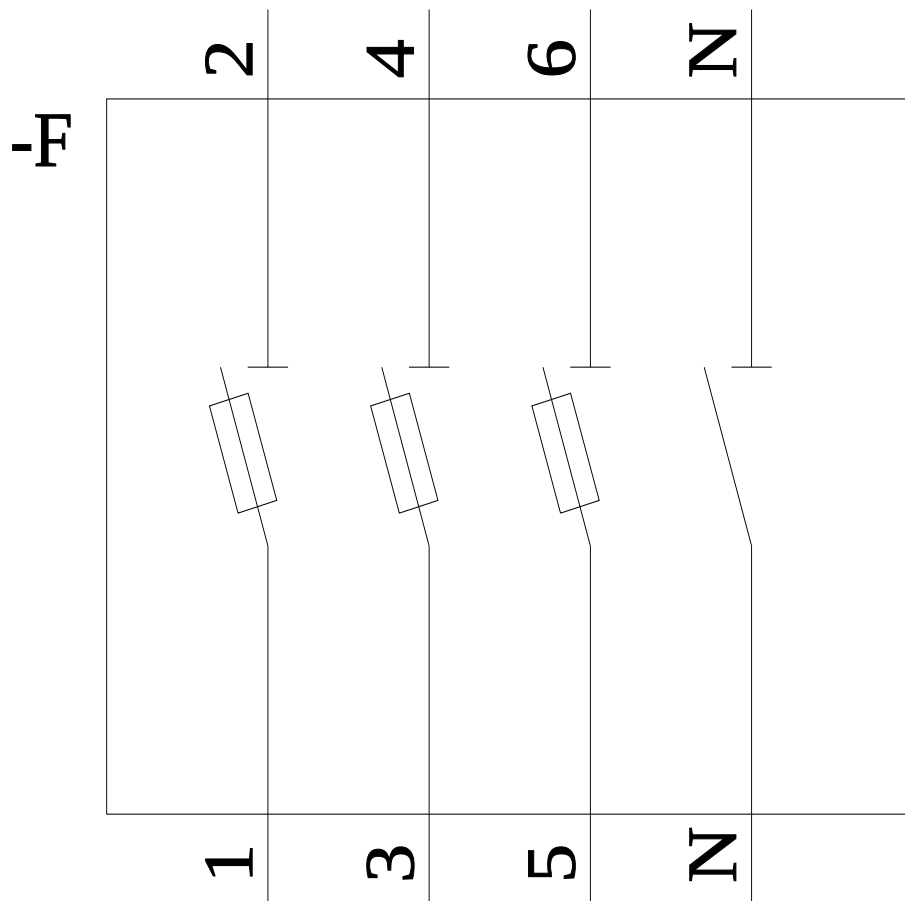

last modified:

5/1/2023 

