


170850 DFM-25-40-P-A-GF Guided drive - Series from 07-2017

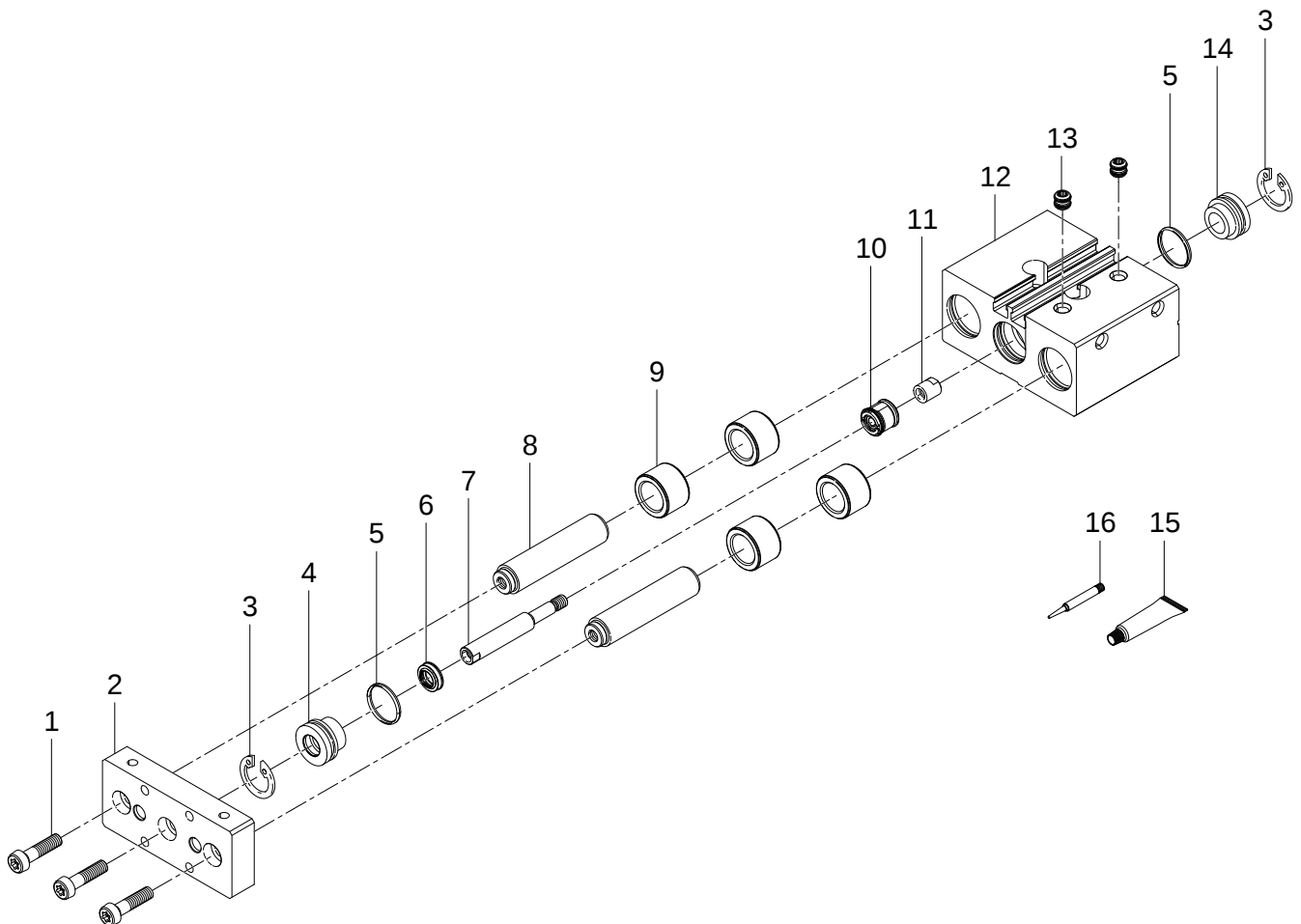

170850 DFM-25-40-P-A-GF Guided drive - Series from 07-2017

Pos.	Part no.	Type	Note	Qty.	Unit
A	8047216	DFM-25-PA :FR 04-2015 Set of wearing parts	Spare parts: 3, 5, 6, 10, 15, 16 ▶ Replacing the wearing parts	1	PC
1		ISO 14580-M6X25-8.8 Socket head screw	Not available Tightening torque 8.2 Nm / 6.0 lbf ft	3	PC
2		DFM-25 End plate	Not available	1	PC
3		J-26 Retaining ring	Not available separately, see position A	2	PC
4		DFM-25 Bearing cap	Not available Grease using during assembly. See position 15	1	PC
5		B-23X1,5-N-NBR75 O-ring ISO3601	Not available separately, see position A Grease using during assembly. See position 15	1	PC
6		WIFC1-10X14X3,7-TPE-U Wiper seal	Not available separately, see position A Grease using during assembly. See position 15	1	PC
7		IRA-10-S0063,3-B Piston rod	Not available	1	PC
8		DFM-25-40-GF Guide rod	Not available	2	PC
9		SINT-B50 16,01X21X20 Cylinder bearing	Not available	4	PC
10		BA-K10D-025-A Complete piston	Not available separately, see position A Grease using during assembly. See position 15	1	PC
11	709442	DSNU-25 Nut	Tightening torque 7 Nm / 5.2 lbf ft Use locking compound. See position 16	1	PC
12		DFM-25-40 Housing	Not available Grease using during assembly. See position 15	1	PC
13	116515	G1/8 Plug screw		2	PC
14		DFM-25 End cap module	Not available	1	PC
15	684474	LUB-KC1 SILIKONFREI 20ML Lubricating grease		1	PC
16	8181256	CYBERBOND TM44 TB1ML Adhesive bonding agent		1	PC