




LED FIL P26X58 E14 0.5W (6W) 50lm 820 Gold

Article number: 146026

BAI LED Filament Pygmy E140.5W 2000K Gold 50lm (6W) 230V-240V 320° 26x58mm LED-lamp

As a specialist, Bailey Lights needs to maintain their reputation in the field of compact lamps. These durable compact LED lamps are often used in elegant fixtures where there is little space for the light source.

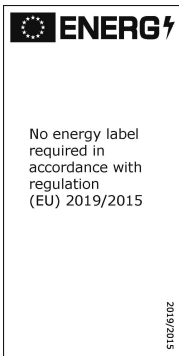

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED FIL P26X58 E14 0.5W (6W) 50lm 820 Gold
Brand	Bailey
Productseries	LED Filament tube
Producttype	P26x58

ETIM specifications

Socket	E14
Luminous flux [lm]	50 - 50
Nominal voltage [V]	220 - 240
Lamp power [W]	0.5 - 0.5
Colour temperature [K]	2000 - 2000
Diameter [mm]	26
Length [mm]	58
Dimmable	No
Lamp shape	Tube, single-ended
Beam angle [°]	320 - 320
Colour	Gold
Type of glass/cover	Clear
Lamp designation	Other
Colour rendering index CRI	90-100
Voltage type	AC
Filament lamp	Yes
Rated luminous flux according to IEC 62612 [lm]	50
Power factor	0.4
Lamp efficacy [lm/W]	25
Nominal current [mA]	6 - 6
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	Other
Average nominal lifetime [h]	15000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	15000
Weighted energy consumption in 1000 hours [kWh]	1
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG0
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	No
Dimming phase cut-on (leading edge)	No
Dimming Touch and Dim	No
Dimming Zigbee	No

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	Not required
With twilight switch	No
Material of light bulb	Glass