




## LED FIL G9 DIM 3.5W (27W) 280lm 922 Clear

Article number: 145241

BAI LED Filament Capsule G9 3.5W 2200K Clear 280lm (27W) Dimmable 230V-240V 922 270° 20x70mm LED-lamp

As a specialist, Bailey Lights needs to maintain their reputation in the field of compact lamps. These durable compact LED lamps are often used in elegant fixtures where there is little space for the light source.

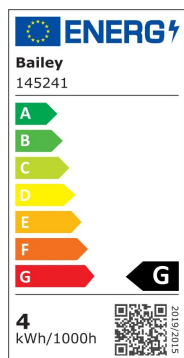

### General ETIM properties

|               |                                           |
|---------------|-------------------------------------------|
| ETIM group    | Lamps                                     |
| ETIM class    | LED-lamp/Multi-LED                        |
| Name          | LED FIL G9 DIM 3.5W (27W) 280lm 922 Clear |
| Brand         | Bailey                                    |
| Productseries | LED Filament capsule                      |
| Producttype   | G9 922 CL                                 |

## ETIM specifications

|                                                 |                     |
|-------------------------------------------------|---------------------|
| Socket                                          | G9                  |
| Luminous flux [lm]                              | 280 - 280           |
| Nominal voltage [V]                             | 220 - 240           |
| Lamp power [W]                                  | 3.5 - 3.5           |
| Colour temperature [K]                          | 2200 - 2200         |
| Diameter [mm]                                   | 20                  |
| Length [mm]                                     | 70                  |
| Dimmable                                        | Yes                 |
| Lamp shape                                      | Tube, single-ended  |
| Beam angle [°]                                  | 270 - 270           |
| Colour                                          | White               |
| Type of glass/cover                             | Clear               |
| Lamp designation                                | Other               |
| Colour rendering index CRI                      | 90-100              |
| Voltage type                                    | AC                  |
| Filament lamp                                   | Yes                 |
| Rated luminous flux according to IEC 62612 [lm] | 280                 |
| Power factor                                    | 0.8                 |
| Lamp efficacy [lm/W]                            | 80                  |
| Nominal current [mA]                            | 17 - 17             |
| Colour of light according to EN 12464-1         | Warm white < 3300 K |
| Housing colour                                  | Colourless          |
| Average nominal lifetime [h]                    | 15000               |
| Degree of protection (IP)                       | IP20                |
| Colour consistency (McAdam ellipse)             | SDCM5               |
| Min. number of switching cycles                 | 100000              |
| Weighted energy consumption in 1000 hours [kWh] | 4                   |
| Remote operation possible                       | No                  |
| With movement sensor                            | No                  |
| With remote control                             | No                  |
| Photobiological safety according to EN 62471    | RG1                 |
| Compatible with Apple HomeKit                   | No                  |
| Compatible with Google Assistant                | No                  |
| Compatible with Amazon Alexa                    | No                  |
| IFTTT support available                         | No                  |
| Suitable for electronic ballast                 | No                  |
| Suitable for magnetic ballast                   | No                  |
| Dimming phase cut-off (trailing edge)           | Yes                 |
| Dimming phase cut-on (leading edge)             | Yes                 |
| Dimming Touch and Dim                           | No                  |
| Dimming Zigbee                                  | No                  |

|                                                              |       |
|--------------------------------------------------------------|-------|
| Dimming Bluetooth                                            | No    |
| Dimming Wi-Fi                                                | No    |
| Energy efficiency class according to EU regulation 2019/2015 | G     |
| With twilight switch                                         | No    |
| Material of light bulb                                       | Glass |

### Alternative articles




**80100038383**  
LED FIL G9 DIM 2.4W (17W)  
160lm 922 Clear




**146033**  
LED G9 Glass DIM 2.2W (25W)  
220lm 822 Clear

### Complementary articles

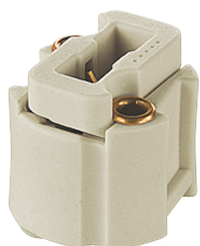

**140268**  
BJB 25.830.1000.00 G9  
Lampholder Ceramic

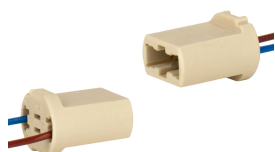

**141211**  
Lampholder G9 6A 250V T250°C  
250mm