

All MULTILOCK, CONNECTOR HOUSING (145)

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts






TE Part # CAT-SIGH262
Signal Header




TE Part # 175062-2
040 MULTILOCK REC CONT. L/P

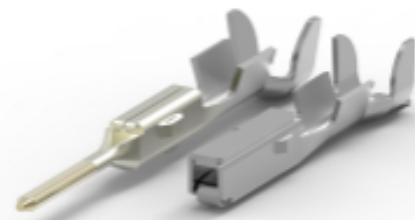

TE Part # CAT-M9194-T273
MULTILOCK, RECEPTACLE AND TAB

TE Part # 175957-1
040 MLC MK-2 DBL PLATE 12P

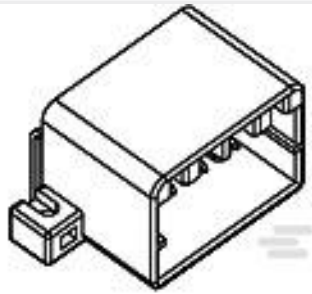

TE Part # 638608-2
CAP ASY, 12 POSN, HORIZONTAL .



TE Part # 1565543-1
040 MLC MK2 12POS CAP ASSY V


Customers Also Bought




TE Part #CAT-T4827-CH8172
Timer Connector Housing



TE Part #1-1534171-1
MQS COVER 2X5P

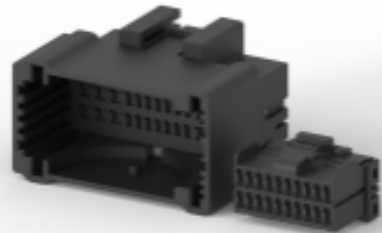

TE Part #CAT-M9194-CH8172
MULTILOCK, CONNECTOR HOUSING

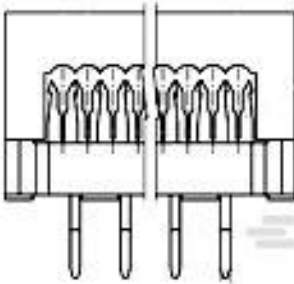


TE Part #1-111382-4
10 DIP PLUG, LEAD FREE

TE Part #5-1897638-5
C.E BOX ASSY-BLM F/L-1FAN,4PW, STD



TE Part #2352245-1
48POS, MQS, REC HSG ASSY, SLD, COD 1

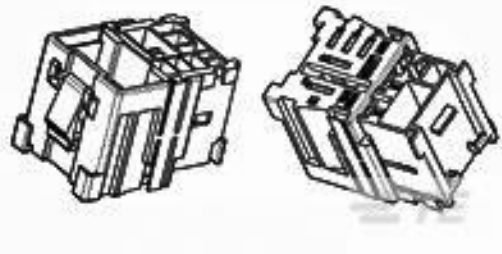

TE Part #284106-2
5P. MODULAR CONN. MICRO RELAY W.



TE Part #2352158-8
32POS, MQS, REC HSG ASSY, SLD, COD 1

Documents

Product Drawings
I/O PLUG ASSY .040 12P
Japanese

CAD Files
Customer View Model
ENG_CVM_175965-1_B1.3d_igs.zip
English
Customer View Model



[ENG_CVM_175965-1_B1.3d_stp.zip](#)

English

Customer View Model

[ENG_CVM_175965-1_B1.2d_dxf.zip](#)

English

3D PDF

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

MULTILOCK Connector System

English

Product Specifications

Application Specification

English

Crimping .040 Series Receptacle Contact

English

Instruction Sheets

Customer Manual (non U.S.)

Japanese

.040 Series Multilock I/O Connector Mark II

Japanese

Customer Manual (non U.S.)

Japanese

.040 Series, Multilock I/O Connector, Mark II

Japanese