


Technical data

KH5070LL/3AS

Ball sleeves



VISUAL (S)

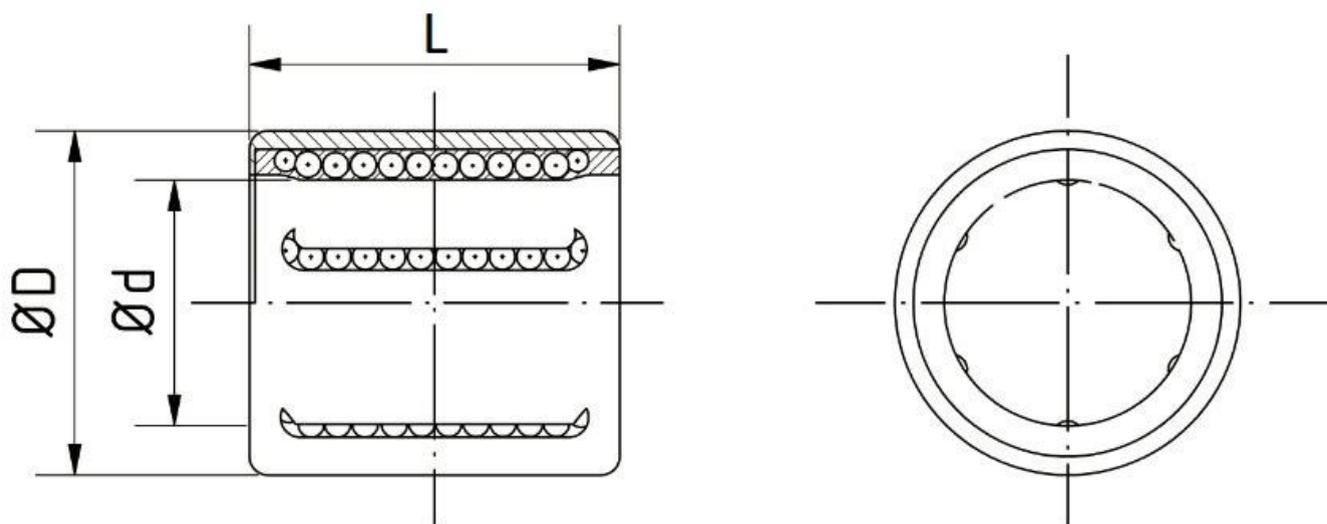

PRODUCT DEFINITION

Brand	NTN
Design type	KH
Ball bushings category	Ball sleeves
Standard	ISO dimension
Number of seals	2
Material outer cylinder or steel segments	hardened steel sleeve
Material Cage	PA
Initial greasing	Non/No
Re-lubricable	Oui/Yes



PRODUCT DEFINITION

d - Internal diameter	50 mm
D - External diameter	62 mm
L - Length	70 mm
Number of ball rows	9
Mass	0,24 kg

PRODUCT PERFORMANCE

Cmin	5300000 mN
Cmax	5300000 mN
C0min	5700000 mN
C0max	5700000 mN
Tmin - Min operating temperature	253,15 °K
Tmax - Max operating temperature	353,15 °K

