


Features

- UL approved Nylon 66, 94V-2
- Color: Red
- Feature: Low Smoke and Halogen Free cable tie suitable for various industry, also household DIY and gardening.
- Application: One piece self-lock cable tie save the time and make effective for installation.
- Easy to thread.

RS PRO Cable Ties

RS Stock No.: 233231

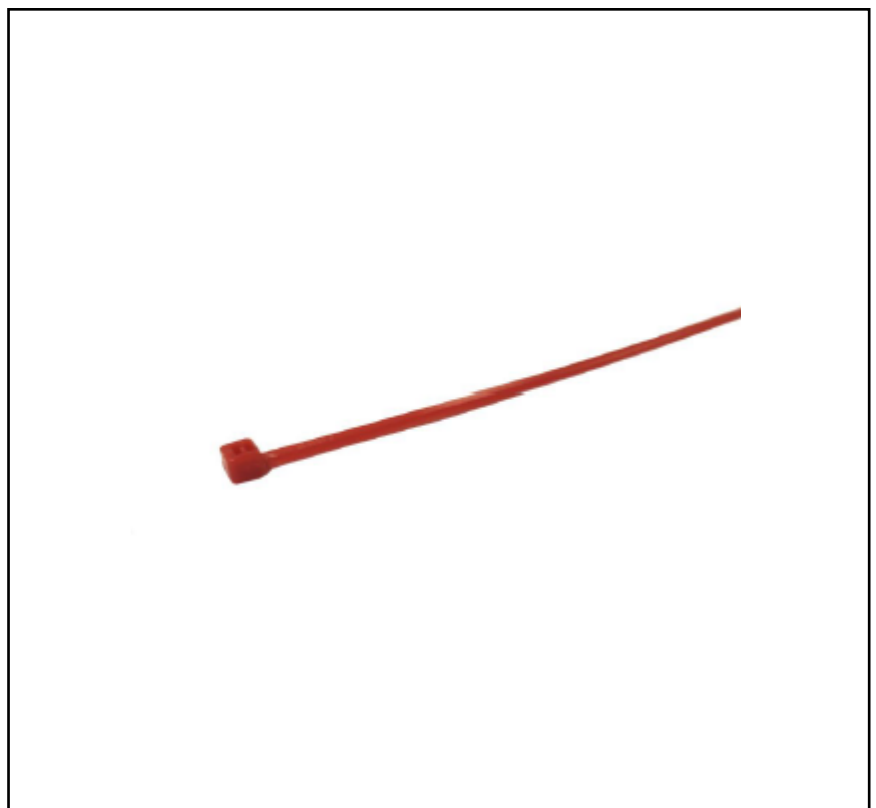

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

- *Material: UL approved Nylon 66 , 94V-2.*
- *Color: Red, other special colors are available upon request.*
- *Feature: Low Smoke and Halogen Free cable tie suitable for various industry, also household DIY and gardening.*
- *Max. operating temperature up to 85 °C*
- *Application: One piece self-lock cable tie save the time and make effective for installation.*

General Specifications

Type	Non-Releasable
Colour	Red
Material	Nylon 66
UV Resistant	No
Minimum Operating Temperature	-40°C
Maximum Operating Temperature	85°C
Fire Behaviour	Self-Extinguishing
Quantity	500

Mechanical Specifications

Length	165mm /6-1/2"
Width	2.5mm / 0.1"
Min. Loop Tensile Strength(lbs/kgf/N)	18lbs / 8kgf / 80N
Maximum Bundle Dia.	43mm

Approvals

Standards Met	UL, RoHS, SVHC, DNV.GL, Lloyd's, CE, VDE, ABS, HF
---------------	---

