

Datasheet

RS PRO HEAT SHRINKABLE-BUTT SPLICE CONNECTORS “HT” (TUBULAR TYPE)

Stock number: 178-7186

MAXIMUM ELECTRIC CURRENT:

A.W.G.	12	10
AMP.	35	50

MAXIMUM ELECTRICAL RATING: 600 VOLTS MAX.


SHRINK TEMP. : 150° C

OPERATING TEMP. : -40° C~+105° C

INSULATION MATERIAL: HIGH DENSITY PE

TERMINAL MATERIAL: COPPER TUBULAR

INSULATION COLOR: YELLOW

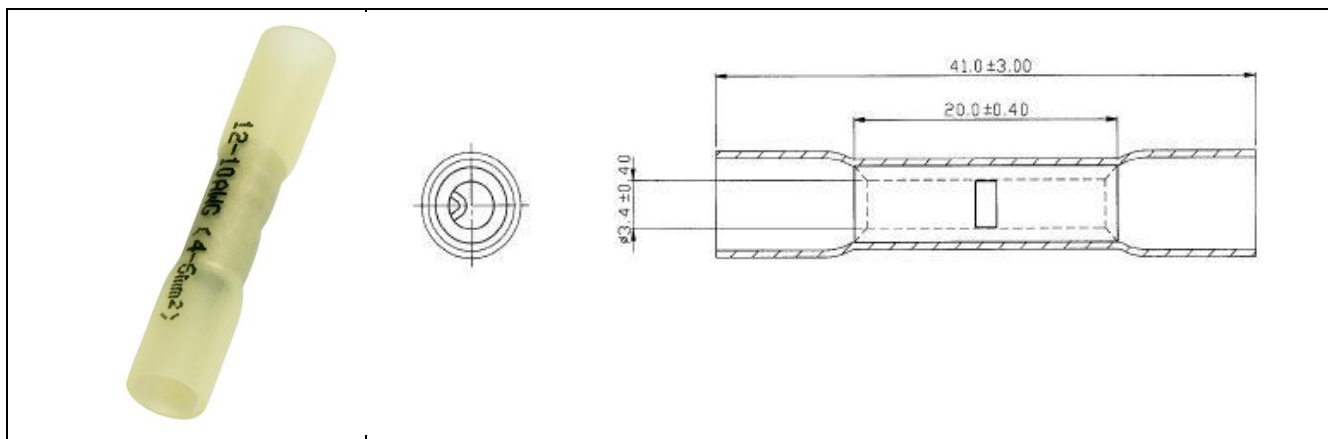

WIRE RANGE A.W.G. mm ²	ITEM NO.	DIMENSION inch(mm)	
		d2	L
12-10 A.W.G. 4-6 mm ²	178-7186	0.134 3.400	1.614 41