

Surface-mounted housing

1461007



General information

Item number	1461007
Model	Surface-mounted housing
Colour	black

Standards/Directives

Certification marks	ERC
---------------------	-----

Operating conditions


Storage temperature	-25°C to +70°C
Operating temperature	-25°C to +40°C
Relative humidity	5 to 95%, no condensation
Degree of protection	IP54

Materials

Housing	PA
---------	----

Connecting cable

Cable diameter, dimension a	7,5-14,5mm
Insulation strip length sheath, dimension b	-
Trim L/N, dimension c	-
Insulation strip length cores, dimension d	-

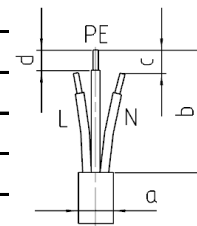


Connection screws

Max. torque for screws housing	0,8 Nm
Screw drive housing	Combined slot/PZ2

For Thermoplastic socket outlet 1461xxx, 1561xxx, 1562xxx, 1661xxx and 1662xxx

Subject to modifications

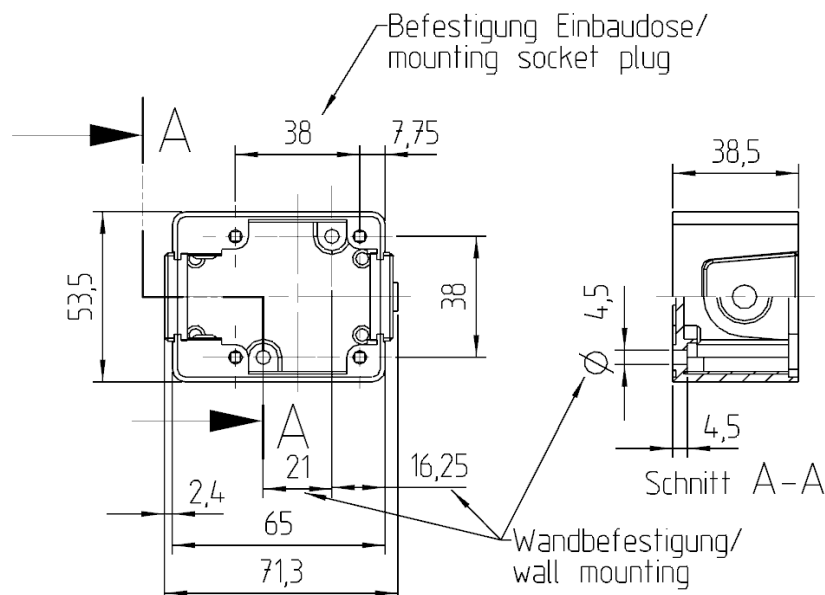

If the application requires extended specifications, we recommend to test the application under real or simulated conditions. Parameters like duration, quantity and temperature will effect the result significantly