




Datasheet
Stock No. 190-2914, 190-2915
RS PRO 70MM SOUNDER MODULE IP65



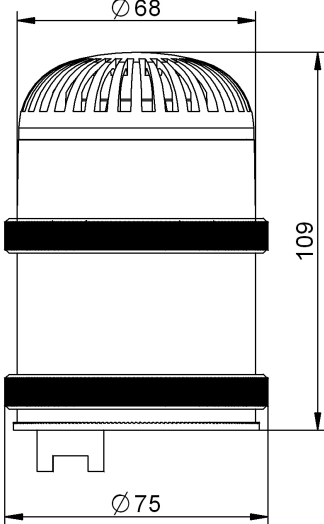
ENGLISH



Acoustic warning device

BODY	PC														
RING	PC														
ACOUSTIC SOURCE	Buzzer														
AVAILABLE COLOURS															
VOLTAGE	12/24V ac/dc - 110/240V ac														
OPERATION	∞														
CURRENT CONSUMPTION	<table border="1"><thead><tr><th></th><th>12V ac</th><th>12V dc</th><th>24V ac</th><th>24V dc</th><th>110V ac</th><th>240V ac</th></tr></thead><tbody><tr><td>mA (Max)</td><td>230</td><td>70</td><td>240</td><td>70</td><td>30</td><td>15</td></tr></tbody></table>		12V ac	12V dc	24V ac	24V dc	110V ac	240V ac	mA (Max)	230	70	240	70	30	15
	12V ac	12V dc	24V ac	24V dc	110V ac	240V ac									
mA (Max)	230	70	240	70	30	15									
ACOUSTIC OUTPUT	Min 78dB(A) – Max 95dB(A)														
SOUND EFFECT	16 sounds (300HZ/2850Hz)														
IP RATING	IP65														

These data are disclosed only for information purposes. RS Components reserves the right to modify them at any time without prior notice.

OPERATING TEMPERATURE	-30°C+60°C
VIBRATIONS	INDUSTRIAL CEI 60068-2-6 SINE
CERTIFICATIONS, APPROVALS	CE
MOUNTING	RING
TECHNICAL DRAWING	

Article Number

Specifications

1902914	70mm Sounder module IP65 piezo 16 x tones 95dB 12-24VAC/DC
1902915	70mm Sounder module IP65 piezo 16 x tones 95dB 110/240VAC