


Geberit Mapress Stainless Steel elbow adaptor 90° with female thread (FKM, blue)



Example image

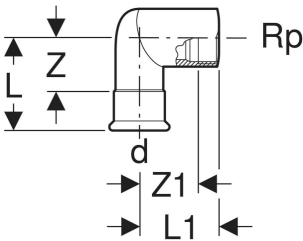

APPLICATION PURPOSES

- For chemicals and technical liquids
- For district heating water ≤ 140 °C
- For thermal media (solar)
- For mineral and lubricating oil
- For motor fuels (e.g. diesel)
- For compressed air (oil purity class 0–4)

- For solar technology, industry and shipbuilding
- For industrial gases (e.g. acetylene, shielding gases)

CHARACTERISTICS

- Pressing indicator
- Silicone-free (LABS-free)
- Seal ring made of FKM, blue

- Pressing socket with black protection plug

TECHNICAL DATA

Product material CrNiMo steel 1.4401 (EN 10088)

ACCESSORIES

- Fastening for Geberit Mapress elbow adaptor 90°

Art. no.	DN	d, ø mm	Rp "	arc °	L cm	L1 cm	Z cm	Z1 cm
50544	12 / 15	15	1/2	90	5.7	3.7	3.7	2.4
50546	15	18	1/2	90	5.7	3.9	3.7	2.6
50549	20	22	3/4	90	6	4.6	3.9	3.1
50552	25	28	1	90	6.7	5.4	4.3	3.7

Art. no.	DN	d _ø mm	R _p "	arc °	L cm	L1 cm	Z cm	Z1 cm
50553	32	35	1 1/4	90	7.5	6.3	4.9	4.4