


# push-in L-connector NPQH-L-Q12-E-P10

Part number: 578274

FESTO

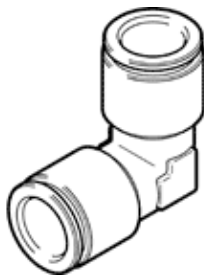

## Data sheet

Feature	Value
Size	Standard
Nominal size	11 mm
Assembly position	Any
Container size	10
Design structure	Push/pull principle
Operating pressure complete temperature range	-0.95 ... 20 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Water as per manufacturer's declaration at <a href="http://www.festo.com">www.festo.com</a>
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	3 - High corrosion stress
Food-safe	See Supplementary material information
Ambient temperature	0 ... 150 °C
Product weight	48.6 g
Pneumatic connection, port 1	for tubing, 12mm outside diameter
Pneumatic connection, port 2	for tubing, 12mm outside diameter
Materials note	Conforms to RoHS
Material housing	Nickel-plated brass
Material release ring	Nickel-plated brass
Material of tubing seal	FPM
Material of tube retaining claw	High alloy steel, non-corrosive