

IVM 40/24-2 (H)

Dual-motor, manoeuvrable and robust middle class IVM 40/24-2 (H) industrial vacuum cleaner for universal use in industrial applications for fine and coarse solid materials.



Order no.

9.989-907.0

- Antistatic equipment

Technical data

EAN code		4054278964010
Power supply	Ph / V / Hz	1 / 220 - 240 / 50 - 60
Air flow	l/s / m³/h	106 / 381.6
Vacuum	mbar / kPa	225 / 22.5
Container capacity	l	40
Container material		Stainless steel
Rated input power	kW	2.3
Vacuuming type		Electric
Connection nominal diameter		DN 70
Accessory nominal diameter		DN 50 / DN 40
Sound pressure level	dB(A)	77
Main filter dust class		M
Filter area for main filter	m²	1.6
Secondary filter dust class		H
Filter area for secondary filter	m²	1.6
Weight without accessories	kg	41
Weight incl. packaging	kg	41.5
Dimensions (L × W × H)	mm	645 × 655 × 1150

This machine requires instruction.

Equipment

Main filter	Star filter
Secondary filter	Cartridge filter
Accessories included in the scope of delivery	no
Container emptying	Set-down trolley

■ Included in the scope of supply.



2 blower motors

- High suction power and robustness.

Mobile stainless steel container

- The deposited container can be conveniently removed from the chassis and driven for disposal/emptying.

Equipped for dust class H for high occupational safety

- Provides effective protection against hazardous dusts from dust class H.

ACCESSORIES FOR IVM 40/24-2 (H)

9.989-907.0



		Order no.	Description	
EMPTYING SUPPORTS				
Emptying bags				
PE emptying bag dia. 540 mm 50 l	1	9.977-885.0		■
ACCESSORY SETS				
Accessory kit for solids/dust				
Oven cleaning accessory kit Expert DN 50	2	9.989-938.0	Accessory kit for oven cleaning: ME hose 3 m (9.989-979.0), handle (9.989-899.0), suction tube (9.989-929.0), floor nozzle (9.989-935.0), reducer (9.989-712.0), adapter (9.993-011.0).	<input type="checkbox"/>
Oven cleaning accessory kit Expert DN 40	3	9.989-939.0	Accessory kit for oven cleaning: ME hose 3 m (9.989-976.0), handle (9.989-898.0), suction tube (9.989-928.0), floor nozzle (9.989-934.0), reducer (9.989-713.0), adapter (9.993-012.0).	<input type="checkbox"/>
Food accessory kit Expert DN 40	4	9.989-940.0	Food accessory kit DN 40: PU hose 3 m (9.989-970.0), handle (9.989-898.0), standard nozzle (9.989-838.0), brush (9.989-879.0), reducer (9.989-713.0), adapter (9.993-012.0).	<input type="checkbox"/>
Food accessory kit Expert DN 50	5	9.989-941.0	Food accessory kit: PU hose 3 m (9.989-973.0), handle (9.989-899.0), standard nozzle (9.989-844.0), brush (9.989-880.0), reducer (9.989-712.0), adapter (9.993-011.0).	<input type="checkbox"/>
Accessory kit for overhead cleaning Expert DN 40	6	9.989-942.0	Accessory kit DN 40 for overhead cleaning: suction tubes (9.989-920.0/9.993-008.0), handles (9.989-916.0/9.989-918.0), standard nozzle (9.989-838.0), brush (9.989-879.0), adapter (9.993-012.0).	<input type="checkbox"/>
Accessory kit for overhead cleaning DN 50 Expert	7	9.989-943.0	Accessory kit DN 50 for overhead cleaning: suction tubes (9.989-921.0/9.993-009.0), handles (9.989-917.0/9.989-919.0), standard nozzle (9.989-844.0), brush (9.989-880.0), adapter (9.993-011.0).	<input type="checkbox"/>
Professional dry floor cleaning set DN40	8	9.990-877.0	Professional dry floor cleaning set: adapter (9.990-874.0), hose (2.889-141.0), bend (2.889-172.0), 2 × suction tube (2.889-194.0), 3 × nozzles (6.906-958.0, 6.903-033.0, 6.902-105.0).	<input type="checkbox"/>
Advanced dry floor cleaning set DN40	9	9.990-893.0	Advanced dry floor cleaning set: EVA hose (9.990-923.0), handle (9.990-929.0), 2 × suction tube (9.990-933.0), floor nozzle (9.990-935.0), standard nozzle (9.980-773.0).	<input type="checkbox"/>
Advanced dry floor cleaning set DN50	10	9.990-894.0	Advanced dry floor cleaning set: EVA hose (9.990-924.0), handle (9.990-930.0), 2 × suction tube (9.990-934.0), floor nozzle (9.990-936.0), standard nozzle (9.980-761.0).	<input type="checkbox"/>
Accessories kit furnace Expert DN35	11	9.991-106.0	Accessory kit for oven cleaning: ME hose 3 m (9.989-976.0), handle (9.989-898.0), suction tube (9.989-928.0), floor nozzle (9.989-934.0), reducer (9.989-713.0), adapter (9.993-012.0).	<input type="checkbox"/>
Accessory kit for solids/dust Expert DN 40	12	9.989-659.0	Accessory kit DN 40 for industrial vacuum cleaners (solids and dust): EVA hose (9.988-088.0), handle (9.977-679.0), standard nozzle (9.988-401.0), reducer (9.989-690.0).	<input type="checkbox"/>
NOZZLES				
Standard nozzles				
Standard nozzle silicone FDA blue DN-F40	13	9.989-835.0		<input type="checkbox"/>
Standard nozzle silicone FDA green DN-F40	14	9.989-836.0		<input type="checkbox"/>

■ Included in the scope of supply. □ Available accessories.

ACCESSORIES FOR IVM 40/24-2 (H)

9.989-907.0



15, 21



16, 22



17, 23



18, 24



13, 19



14, 20



25-26



27-28

	Order no.	Description	
NOZZLES			
Standard nozzles			
Standard nozzle silicone FDA red DN-F40	15	9.989-837.0	<input type="checkbox"/>
Standard nozzle silicone FDA transparent DN-F40	16	9.989-838.0	<input type="checkbox"/>
Standard nozzle silicone FDA white DN-F40	17	9.989-839.0	<input type="checkbox"/>
Standard nozzle silicone FDA yellow DN-F40	18	9.989-840.0	<input type="checkbox"/>
Standard nozzle silicone FDA blue DN-F50	19	9.989-841.0	<input type="checkbox"/>
Standard nozzle silicone FDA green DN-F50	20	9.989-842.0	<input type="checkbox"/>
Standard nozzle silicone FDA red DN-F50	21	9.989-843.0	<input type="checkbox"/>
Standard nozzle silicone FDA transparent DN-F50	22	9.989-844.0	<input type="checkbox"/>
Standard nozzle silicone FDA white DN-F50	23	9.989-845.0	<input type="checkbox"/>
Standard nozzle silicone FDA yellow DN-F50	24	9.989-846.0	<input type="checkbox"/>
Floor nozzles			
Floor nozzle stainless steel AISI 304 DN-F40 blue	25	9.989-861.0	<input type="checkbox"/>
Floor nozzle stainless steel AISI 316L DN-F50 blue	26	9.989-862.0	<input type="checkbox"/>
Floor nozzle stainless steel AISI 316L DN-F40 green	27	9.989-863.0	<input type="checkbox"/>
Floor nozzle stainless steel AISI 316L DN-F50 green	28	9.989-864.0	<input type="checkbox"/>

■ Included in the scope of supply. □ Available accessories.

ACCESSORIES FOR IVM 40/24-2 (H)

9.989-907.0



29-30



31-32




33-34



35-36



37-38

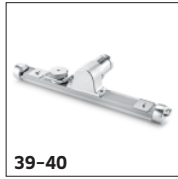

39-40



41-42

	Order no.	Description	
NOZZLES			
Floor nozzles			
Floor nozzle stainless steel AISI 316L DN-F40 red	29	9.989-865.0	<input type="checkbox"/>
Floor nozzle stainless steel AISI 316L DN-F50 red	30	9.989-866.0	<input type="checkbox"/>
Floor nozzle stainless steel AISI 316L DN-F40 transparent	31	9.989-867.0	<input type="checkbox"/>
Floor nozzle stainless steel AISI 316L DN-F50 transparent	32	9.989-868.0	<input type="checkbox"/>
Floor nozzle stainless steel AISI 316L DN-F40 white	33	9.989-869.0	<input type="checkbox"/>
Floor nozzle stainless steel AISI 316L DN-F50 white	34	9.989-870.0	<input type="checkbox"/>
Floor nozzle stainless steel AISI 316L DN-F40 yellow	35	9.989-871.0	<input type="checkbox"/>
Floor nozzle stainless steel AISI 316L DN-F50 yellow	36	9.989-872.0	<input type="checkbox"/>
Floor nozzle stainless steel AISI 316L DN-F40	37	9.989-914.0	<input type="checkbox"/>
Floor nozzle stainless steel AISI 316L DN-F50	38	9.989-915.0	<input type="checkbox"/>
Floor nozzle stainless steel 400 mm DN-F40	39	9.989-934.0	<input type="checkbox"/>
Floor nozzle stainless steel 400 mm DN-F50	40	9.989-935.0	<input type="checkbox"/>
Floor nozzle aluminium 400 mm DN-F40	41	9.989-936.0	<input type="checkbox"/>
Floor nozzle aluminium 400 mm DN-F50	42	9.989-937.0	<input type="checkbox"/>

■ Included in the scope of supply. □ Available accessories.

ACCESSORIES FOR IVM 40/24-2 (H)

9.989-907.0



	Order no.	Description	
NOZZLES			
Flexible crevice nozzles			
Crevice nozzle flexible silicone FDA DN-F50 transparent	43	9.989-847.0	<input type="checkbox"/>
Crevice nozzle flexible silicone FDA DN-F40 transparent	44	9.989-848.0	<input type="checkbox"/>
Surface nozzles			
Silicone surface nozzle FDA blue DN-F40	45	9.989-849.0	<input type="checkbox"/>
Silicone surface nozzle FDA blue DN-F50	46	9.989-850.0	<input type="checkbox"/>
Silicone surface nozzle FDA green DN-F40	47	9.989-851.0	<input type="checkbox"/>
Silicone surface nozzle FDA green DN-F50	48	9.989-852.0	<input type="checkbox"/>
Silicone surface nozzle FDA red DN-F40	49	9.989-853.0	<input type="checkbox"/>
Silicone surface nozzle FDA red DN-F50	50	9.989-854.0	<input type="checkbox"/>
Silicone surface nozzle FDA transparent DN-F40	51	9.989-855.0	<input type="checkbox"/>
Silicone surface nozzle FDA transparent DN-F50	52	9.989-856.0	<input type="checkbox"/>
Silicone surface nozzle FDA white DN-F40	53	9.989-857.0	<input type="checkbox"/>
Silicone surface nozzle FDA white DN-F50	54	9.989-858.0	<input type="checkbox"/>
Silicone surface nozzle FDA yellow DN-F40	55	9.989-859.0	<input type="checkbox"/>
Silicone surface nozzle FDA yellow DN-F50	56	9.989-860.0	<input type="checkbox"/>

■ Included in the scope of supply. □ Available accessories.

ACCESSORIES FOR IVM 40/24-2 (H)

9.989-907.0



	Order no.	Description	
BRUSHES			
End brushes			
Brush FDA blue ø 75 mm DN-F40	57	9.989-873.0	<input type="checkbox"/>
Brush FDA blue ø 75 mm DN-F50	58	9.989-874.0	<input type="checkbox"/>
Brush FDA green ø 75 mm DN-F40	59	9.989-875.0	<input type="checkbox"/>
Brush FDA green ø 75 mm DN-F50	60	9.989-876.0	<input type="checkbox"/>
Brush FDA red ø 75 mm DN-F40	61	9.989-877.0	<input type="checkbox"/>
Brush FDA red ø 75 mm DN-F50	62	9.989-878.0	<input type="checkbox"/>
Brush FDA white ø 75 mm DN-F40	63	9.989-879.0	<input type="checkbox"/>
Brush FDA white ø 75 mm DN-F50	64	9.989-880.0	<input type="checkbox"/>
Brush FDA yellow ø 75 mm DN-F40	65	9.989-881.0	<input type="checkbox"/>
Brush FDA yellow ø 75 mm DN-F50	66	9.989-882.0	<input type="checkbox"/>
Cylinder brushes			
Cylinder brush ø 100 mm DN-F40	67	9.989-922.0	<input type="checkbox"/>
Cylinder brush ø 200 mm DN-F40	68	9.989-923.0	<input type="checkbox"/>
Cylinder brush ø 100 mm DN-F50	69	9.989-925.0	<input type="checkbox"/>
Cylinder brush ø 200 mm DN-F50	70	9.989-926.0	<input type="checkbox"/>

Available accessories.

ACCESSORIES FOR IVM 40/24-2 (H)

9.989-907.0



71-75



76-79



80-81, 83



82



84-85

	Order no.	Description	
HOSES			
ME-Schläuche			
Hose ME DN40 3 m	71	9.989-976.0	<input type="checkbox"/>
Hose ME DN40 5 m	72	9.989-977.0	<input type="checkbox"/>
Hose without connection ME DN40 15 m	73	9.989-978.0	<input type="checkbox"/>
Hose ME DN50 3 m	74	9.989-979.0	<input type="checkbox"/>
Hose ME DN50 5 m	75	9.989-980.0	<input type="checkbox"/>
PVC			
Hose PVC DN40 3 m	76	9.989-962.0	<input type="checkbox"/>
Hose PVC DN40 5 m	77	9.989-963.0	<input type="checkbox"/>
Hose PVC DN50 3 m	78	9.989-964.0	<input type="checkbox"/>
Hose PVC DN50 5 m	79	9.989-965.0	<input type="checkbox"/>
EVA hoses			
Hose EVA DN40 3 m	80	9.989-982.0	<input type="checkbox"/>
Hose EVA DN40 5 m	81	9.989-983.0	<input type="checkbox"/>
Hose EVA DN50 3 m	82	9.989-984.0	<input type="checkbox"/>
Hose EVA DN50 5 m	83	9.989-985.0	<input type="checkbox"/>
Hose installation sets			
Hose connection kit, stainless steel AISI 304 DN40	84	9.989-986.0	Hose connection kit in nominal width DN 40, made of stainless steel. Contents: 1 hose connection piece, 1 hose connection (rotating), 2 hose clamps, 2 hose end pieces (black), 1 flat bag (PE plastic).

Available accessories.

ACCESSORIES FOR IVM 40/24-2 (H)

9.989-907.0



	Order no.	Description		
HOSES				
Hose installation sets				
Hose connection kit, stainless steel AISI 304 DN50	85	9.989-987.0	Hose connection kit in nominal width DN 50, made of stainless steel. Contents: 1 hose connection piece, 1 hose connection (rotating), 2 hose clamps, 2 hose end pieces (black), 1 flat bag (PE plastic).	<input type="checkbox"/>
PU hoses				
Hose PU DN40 3 m	86	9.989-966.0		<input type="checkbox"/>
Hose PU DN40 5 m	87	9.989-967.0		<input type="checkbox"/>
Hose PU DN50 3 m	88	9.989-968.0		<input type="checkbox"/>
Hose PU DN50 5 m	89	9.989-969.0		<input type="checkbox"/>
Hose PU FDA DN40 3 m	90	9.989-970.0		<input type="checkbox"/>
Hose PU FDA DN40 5 m	91	9.989-971.0		<input type="checkbox"/>
Hose PU FDA DN40 15 m	92	9.989-972.0		<input type="checkbox"/>
Hose PU FDA DN50 3 m	93	9.989-973.0		<input type="checkbox"/>
Hose PU FDA DN50 5 m	94	9.989-974.0		<input type="checkbox"/>
Hose PU FDA DN50 15 m	95	9.989-975.0		<input type="checkbox"/>
ME-PU-hoses				
Hose without connection ME DN50 15 m	96	9.989-981.0		<input type="checkbox"/>
HANDLES				
Handle stainless steel AISI 304 DN40	97	9.989-896.0		<input type="checkbox"/>
Handle stainless steel AISI 304 DN50	98	9.989-897.0		<input type="checkbox"/>

Available accessories.

ACCESSORIES FOR IVM 40/24-2 (H)

9.989-907.0




99-100




101-102




103-104

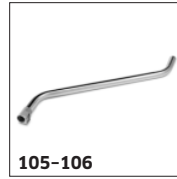

105-106

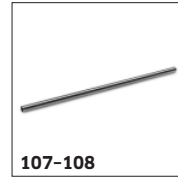

107-108

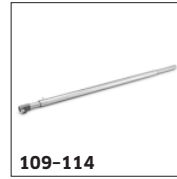

109-114

	Order no.	Description	
HANDLES			
Handle straight stainless steel AISI 304 DN40	99	9.989-898.0	<input type="checkbox"/>
Handle straight stainless steel AISI 304 DN50	100	9.989-899.0	<input type="checkbox"/>
Handle carbon 45° DN-F40	101	9.989-916.0	<input type="checkbox"/>
Handle carbon 45° DN-F50	102	9.989-917.0	<input type="checkbox"/>
Handle carbon 110° DN-F40	103	9.989-918.0	<input type="checkbox"/>
Handle carbon 110° DN-F50	104	9.989-919.0	<input type="checkbox"/>
SUCTION TUBES			
Suction tube stainless steel AISI 304 DN40	105	9.989-912.0	<input type="checkbox"/>
Suction tube stainless steel AISI 304 DN50	106	9.989-913.0	<input type="checkbox"/>
Suction tube carbon 1500 mm DN-F40 conical	107	9.989-920.0	<input type="checkbox"/>
Suction tube carbon 1500 mm DN-F50 conical	108	9.989-921.0	<input type="checkbox"/>
Suction tube aluminium high temperature 1000 mm DN-F40	109	9.989-928.0	<input type="checkbox"/>
Suction tube aluminium high temperature 1000 mm DN-F50	110	9.989-929.0	<input type="checkbox"/>
Suction tube aluminium high temperature 2000 mm DN-F40	111	9.989-930.0	<input type="checkbox"/>
Suction tube aluminium high temperature 2000 mm DN-F50	112	9.989-931.0	<input type="checkbox"/>

Available accessories.

ACCESSORIES FOR IVM 40/24-2 (H)

9.989-907.0



	Order no.	Description	
SUCTION TUBES			
Suction tube aluminium high temperature 3000 mm DN-F40	113	9.989-932.0	<input type="checkbox"/>
Suction tube aluminium high temperature 3000 mm DN-F50	114	9.989-933.0	<input type="checkbox"/>
ADAPTERS / REDUCERS / DISTRIBUTORS			
Accessories adapter			
Adapter DN70 auf Bajonett 2.0 elektr. leitend	115	9.990-874.0	<input type="checkbox"/>
Reducers/expanders			
Reducer in AISI 304 stainless steel DN50 to DN40	116	9.989-893.0	<input type="checkbox"/>
Stainless steel reducer DN 70 to DN 50	117	9.989-712.0	<input type="checkbox"/>
Stainless steel reducer DN 70 to DN 40	118	9.989-713.0	<input type="checkbox"/>
Distributor			
AISI 304 stainless steel manifold DN70 to DN50	119	9.989-894.0	<input type="checkbox"/>
AISI 304 stainless steel manifold DN70 to DN40	120	9.989-895.0	<input type="checkbox"/>
FILTERS			
Cartridge filter			
Cartridge filter PE H14 1,6m²	121	9.993-005.0	<input type="checkbox"/>

Available accessories.