

molex


Part Number : [588660002](#)

Product Description : HMC Rectangular Industrial End Bell Cap Assembly, PG36, 14.00-18.00mm dia. Wire Size, Blue Bush, for External Threaded Hoods

Series Number : 58866

Status : Obsolete

Product Category : I/O Connectors

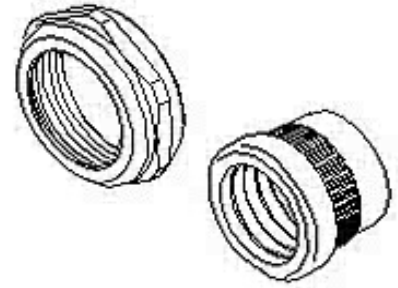

Documents & Resources

[588660002_stp.zip](#)

Specifications

[PS-58719-005-001.pdf](#)

[PS-58719-006-001.pdf](#)

Product Environment Compliance

Compliance

| | |
|--------------------|--------------------|
| GADSL/IMDS | Product not active |
| China RoHS | Product not active |
| EU ELV | Product not active |
| Low-Halogen Status | Product not active |
| REACH SVHC | Product not active |
| EU RoHS | Product not active |

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

| | |
|----------------|--|
| Status | Obsolete |
| Category | I/O Connectors |
| Series | 58866 |
| Description | HMC Rectangular Industrial End Bell Cap Assembly, PG36, 14.00-18.00mm dia. Wire Size, Blue Bush, for External Threaded Hoods |
| Application | Panel-Mount |
| Component Type | Bell Cap Assembly |
| Product Name | HMC |
| Type | N/A |
| UPC | 800756018140 |

Electrical

| | |
|-------------------------------|-----|
| Current - Maximum per Contact | N/A |
|-------------------------------|-----|

Physical

| | |
|---------------------------|-----------|
| Circuits (Loaded) | 48, 72 |
| Color - Resin | Blue |
| Lock to Mating Part | Yes |
| Material - Metal | Brass |
| Material - Plating Mating | N/A |
| Material - Resin | PVC |
| Net Weight | 156.000/g |
| Orientation | Vertical |
| Packaging Type | Bag |
| Panel Mount | N/A |
| Pitch - Mating Interface | N/A |
| Polarized to Mating Part | Yes |

| | |
|-----------------------------|------|
| Termination Interface Style | N/A |
| Waterproof / Dustproof | Yes |
| Waterproof / Dustproof Type | IP65 |

Mates With / Use With

Use with Part(s)

| Description | Part Number |
|---|------------------|
| HMC Rectangular Industrial Hood, Multi-Module Type, Vertical, External Thread, 48-72 Circuits | <u>587230010</u> |

This document was generated on Aug 11, 2025

Obsolete