



Accessories T4 - T5 Mechanical

Acc.

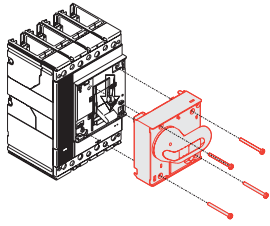

KT5RH

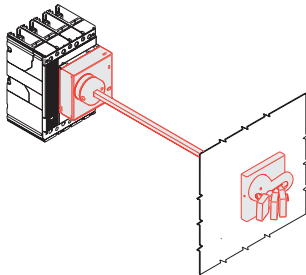

KT5VD-M, OXP10X225
KT5VD-H



KT5PFVR



KT5WMK



KT5WFVR

Direct mount rotary operator handle

Direct mount rotary handle (for fixed and plug-in breakers)
Direct mount rotary handle (for withdrawable breakers)

	Catalog number	List price
Direct mount rotary handle (for fixed and plug-in breakers)	KT5RH	
Direct mount rotary handle (for withdrawable breakers)	KT5RHW	

Early make contact

Frame	Catalog number	List price
T4-T5	KT5EM	

Allows the UVR or control to be supplied in advance. Mounted inside the direct rotary handle.

Variable depth rotary handles

Mechanism	Catalog number	List price
Nema 1, 12, 3R Handle (Black)	OHB125J10X ①	
Nema 4, 4X Handle (Black)	OHB125L10 ①	
Shaft - 148 mm / 5.8 in	OSP10X148 ①	
Shaft - 225 mm / 8.9 in	OSP10X225 ①	
Shaft - 500 mm / 19.7 in	OSP10X500 ①	
Nema 1 handle square profile	KT5VD-H	

Plug-in kits

Breaker	Breaker adapter kit		Plug-in base	
	Catalog number	List price	Catalog number	List price
3-pole	T4 3 Pole with extended front terminal	KT4PMK	KT4PFEF	
	T4 3 Pole with rear horizontal terminal		KT4PFHR	
	T4 3 Pole with rear vertical terminal		KT4PFVR	
3-pole	T5 3 Pole with extended front terminal	KT5PMK	KT5PFEF	
	T5 3 Pole with rear horizontal terminal		KT5PFHR	
	T5 3 Pole with rear vertical terminal		KT5PFVR	
4-pole	T4 4 Pole with extended front terminal	KT4PMK-4	KT4PFEF-4	
	T4 4 Pole with rear horizontal terminal		KT4PFHR-4	
	T4 4 Pole with rear vertical terminal		KT4PFVR-4	
4-pole	T5 4 Pole with extended front terminal	KT5PMK-4	KT5PFEF-4	
	T5 4 Pole with rear horizontal terminal		KT5PFHR-4	
	T5 4 Pole with rear vertical terminal		KT5PFVR-4	

Draw-out kits

Breaker	Breaker adapter kit		Draw-out base	
	Catalog number	List price	Catalog number	List price
3-pole	T4 3 Pole with extended front terminal	KT4WMK	KT4WFEF	
	T4 3 Pole with rear horizontal terminal		KT4WFHR	
	T4 3 Pole with rear vertical terminal		KT4WFVR	
3-pole	T5 3 Pole with extended front terminal	KT5WMK	KT5WFEF	
	T5 3 Pole with rear horizontal terminal		KT5WFHR	
	T5 3 Pole with rear vertical terminal		KT5WFVR	
4-pole	T4 4 Pole with extended front terminal	KT4WMK-4	KT4WFEF-4	
	T4 4 Pole with rear horizontal terminal		KT4WFHR-4	
	T4 4 Pole with rear vertical terminal		KT4WFVR-4	
4-pole	T5 4 Pole with extended front terminal	KT5WMK-4	KT5WFEF-4	
	T5 4 Pole with rear horizontal terminal		KT5WFHR-4	
	T5 4 Pole with rear vertical terminal		KT5WFVR-4	

Direct mount rotary operator or front locking device or motor operator is required for the draw-out configuration.

Terminal covers for fixed part of circuit-breakers (kit of 2)

Breaker	3-pole		4-pole	
	Catalog number	List price	Catalog number	List price
T4	KT4TCFP-3		KT4TCFP-4	
T5	KT5TCFP-3		KT5TCFP-4	

Mechanical interlock plate

	Catalog number	List price
Frame unit horizontal interlock - HB	KT5MI-H	
Frame unit vertical interlock - VB	KT5MI-V	
Plate for A interlock - T4 (F-P-W) + T4 (F-P-W)	KT5MIP-A	
Plate for B interlock - T4 (F-P-W) + T5 400A (F-P-W) or T5 600A (F)	KT5MIP-B	
Plate for C interlock - T4 (F-P-M) + T5 600A (P-W)	KT5MIP-C	
Plate for D interlock - T5 400A (F-P-M) or T5 600A (F) + T5 400A (F-P-M) or T5 600A (F)	KT5MIP-D	
Plate for E interlock - T5 400A (F-P-M) or T5 600A (F) + T5 600A (P-W)	KT5MIP-E	
Plate for F interlock - T5 600A (P-W) + T5 600A (P-W)	KT5MIP-F	

Discount schedule DS-STA

① Discount schedule DS-H - Handles