


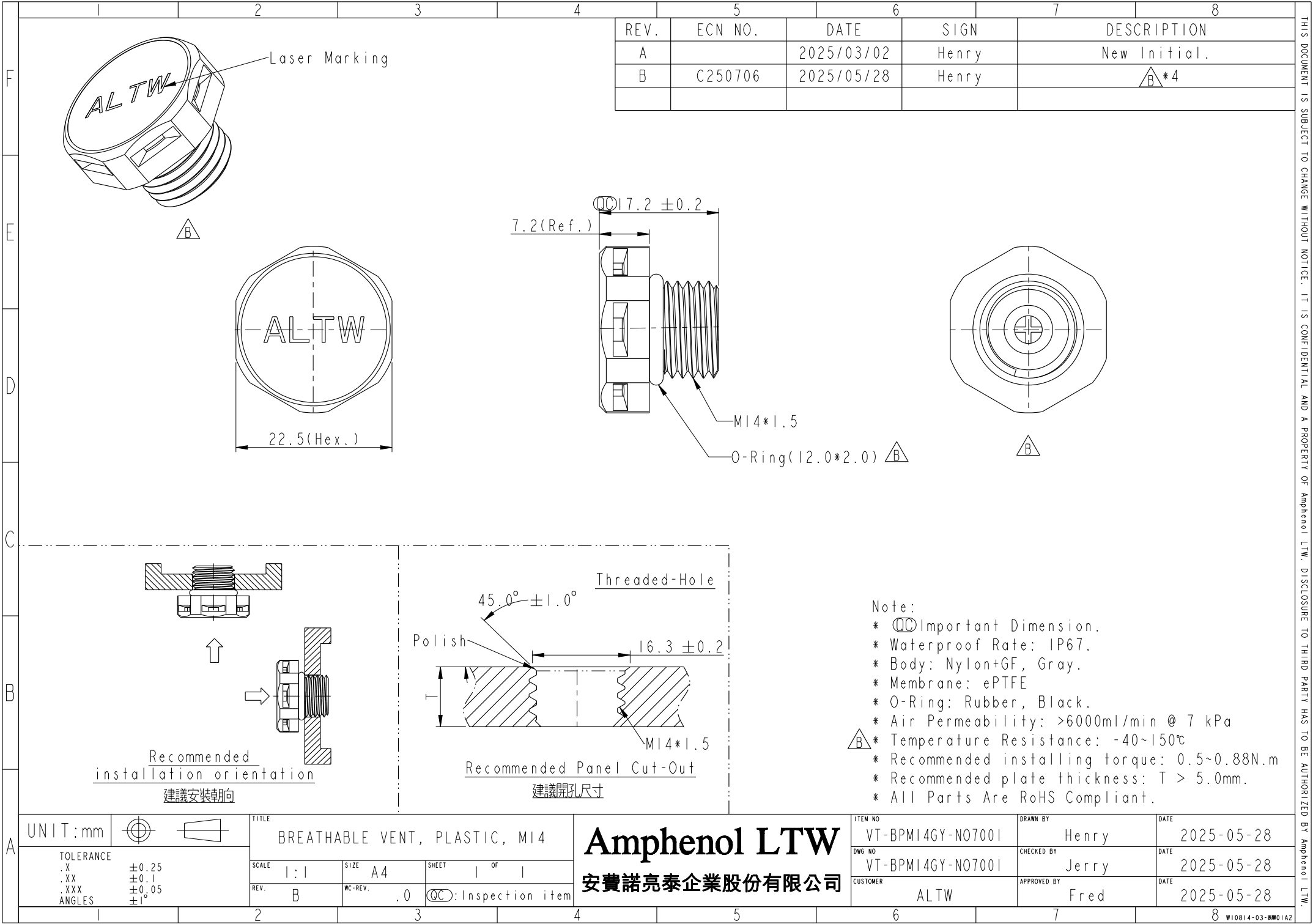

Note:

- * Ⓞ Important Dimension.
- * Waterproof Rate: IP67.
- * Body: Nylon+GF, Gray.
- * Membrane: ePTFE
- * O-Ring: Rubber, Black.
- * Air Permeability: >6000ml/min@ 7 kPa
- * Temperature Resistance: -40~150℃
- * Recommended installing torque: 0.5~0.88N.m
- * Recommended plate thickness: T > 5.0mm.
- * All Parts Are RoHS Compliant.

Amphenol LTW
安費諾亮泰企業股份有限公司

THIS DOCUMENT IS SUBJECT TO CHANGE WITHOUT NOTICE. IT IS CONFIDENTIAL AND A PROPERTY OF Amphenol LTW. DISCLOSURE TO THIRD PARTY HAS TO BE AUTHORIZED BY Amphenol LTW.