



4750
LUMEN



1 1/2 - 6H
RUNTIME



80M
RANGE



IP65/IK07
IP RATING


SLR-4750 - INDUSTRIAL SITE LIGHT

- 4750 Lumen 50W white COB LED, 6500k
- Dual power - rechargeable & mains
- USB Power bank function
- Super tough aluminium structure with protective rubber edging
- Ultra tough IK07 shock resistant
- Built-in aluminium heat sink fins
- 180° adjustable aluminium handle/stand
- Battery level and charging indicator lights
- Mains multi-country charger/power lead included
- 4 1/2 hours charge time
- Adjustable tripods & magnet attachments available

BATTERY 11.1v 5200mAh Li-ion Rechargeable Battery

WEIGHT 1135g

DIMENSION 60 x 261 x 237mm

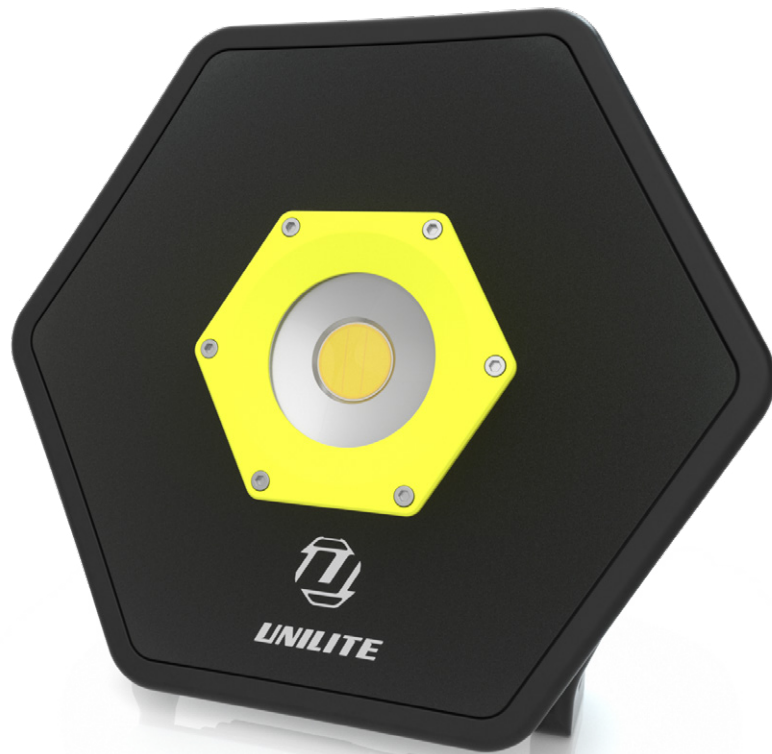

USB POWER BANK FACILITY