

compact Pin Busbar, 10mm² connection: 1p/N AFDD 5SM6 + RCBO
2-pole + auxiliary switch 0,5-pole touch protected 1000mm cuttable



Versie	
productmerksnaam	SENTRON
Algemene technische gegevens	
aantal fasen	1
Elektriciteit	
continustroom / nominale waarde	63 A
Hoofd-circuit	
bedrijfsspanning / nominale waarde / maximaal	230 V
Geschiktheid	
geschiktheid voor samenwerking	
• apparaten met hulpschakelaar	Ja
• apparaten met nulgeleider	Ja
Product Details	
producteigenschap / elektrisch geïsoleerd	Ja
Aantal	
aantal apparaten / geschikt voor aanbouw	17

Aansluitingen

uitvoering van de elektrische aansluiting	Stift
---	-------

Mechanical Design

verdelingsmaat	3,5 mm
hoogte	13 mm
lengte	956,5 mm
nettogewicht	373 g

Certificaten

Declaration of Conformity



EG-Konf.

Verdere informatie

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/nl/nl/Catalog/product?mlfb=5ST3786-0>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/nl/ps/5ST3786-0>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=5ST3786-0

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

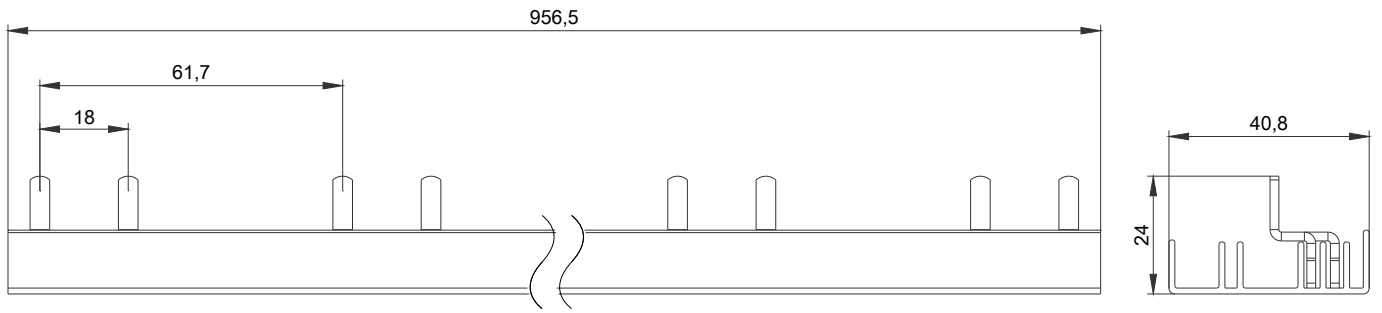

5ST3786-0

