

# BODY CAR TOOL SET

JET.CRTCAR2

IN BULK



- 200H.50PB Rivoir Hammer
- 209.50 Wood Mallet
- 860H.28 Round-head Packing Hammer
- 861D.30 Postilion Hammer
- 862D.60 Flat Bat
- 868D.40BOP Hammer with Bent Tip and Round Domed Head-
- 867D.DS Swaging Bat
- 870B American Heap
- 871B.45 Heap Thin Comma
- 874A Heap Sole
- 906A Punching Heap
- 875.3 Debossing Pallet
- 893B.319PB Tape measure
- 850.S350 Milled File
- 851C File Mount
- CR.D1 Unhooker Pliers
- CR.D10 Wiper arm extractor
- CR.D4PB Scrapper Set
- CR.D5PB Stripping Tool Set
- AR.SPJ4PB Set of 4 Precision Levers
- 235.J1PB Set of 3 stainless steel scrapers
- 844.S9 9 mm Ccutters Snap-off blade
- 876A Double sppen deboss pallet
- U50030013Q Plastic box x3



SKU	SKU Desc	EAN Code	RRP
JET.CRTCAR2	ROLLER CABINET - JET - BODY CAR STATION - Tooled - 4 Module Per Drawer - RED	3662424115868	€xx.xx

# BODY CAR TOOL SET

AUTO-TRUCK



## DRAWER 1


<b>1/4"</b>	R.H. 5.5 – 6 – 7 – 8 – 9 – 10 – 11 – 12 – 13 14 mm R.HLA Deep : 8 – 10 - 13 mm	RL.161 R.150A R.180	R.235	R.209 - 55 mm R.210 - 100 mm	R.240		R.236CA
<b>1/2"</b>	S.H. 8 to 32 mm	SL.161			S.120A	S.240A	
	PH1 PH2 PH3  PZ1 PZ2 PZ3	ECR  ES 4.5-6.5-8 mm	EH3 EH4 EH5 EH6 EH7	EXR10 EXR15 EXR20 EXR25 EXR27 EXR30 EXR40			

	<b>181A.25CPE</b> – Multi Grip CPE 181A Plier   <b>185A.20CPE</b> - Half round nose 200 mm Mono material   <b>192A.16CPE</b> - Diagonal cutters - High performance   <b>501B</b> – Locking Grip
	<b>440.7</b> – 8 – 9 – 10 – 11 – 12 – 13 – 14 – 16 – 17 – 18- 19 mm <b>467S</b> 8-10-11-12-13-14 mm
	<b>83SH.</b> 1,5 - 2,0 - 2,5 - 3,0 - 4,0 - 5,0 - 6,0 - 8,0 – 10 mm



SKU	SKU Desc	EAN Code	RRP
JET.CRTCAR2	ROLLER CABINET - JET - BODY CAR STATION - Tooled - 4 Module Per Drawer - RED	3662424115868	€xx.xx

# BODY CAR TOOL SET


AUTO-TRUCK

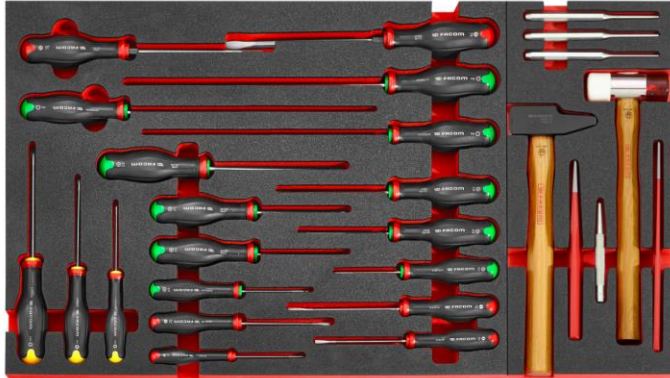

## DRAWER 2

  	<ul style="list-style-type: none"> <li>● 3X75 - 3.5X100 - 4X100 - 5.5X125 <b>Powerful Serie</b> 5x150 – 8X175</li> <li>⊕ PH 0X75 1X100 2X125</li> <li>✦ TT10 15 20 25 27 30 40</li> <li>♻ T20 30 40</li> </ul>
	<p><b>200H.32PB</b>, Hickory rivoir Hammer   <b>208A.32CBA</b>, Interchangeable Sledgehammers   <b>248</b> Pin Driver 4, 5, 6 mm   <b>256</b> Precision Punch 6 mm   <b>259</b> Extra-flat Chisel   <b>263</b> Constant-profile Thin Chisels</p>

Delivered with

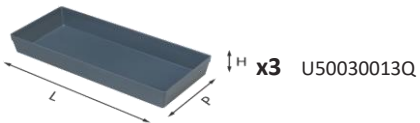

SKU	SKU Desc	EAN Code	RRP
JET.CRTCAR2	ROLLER CABINET - JET - BODY CAR STATION - Tooled - 4 Module Per Drawer - RED	3662424115868	€xx.xx