


Data sheet

Commercial Art.No.: 92.030.0953.1

distributor GST18I3V 5P1 BV SW

gesis® CLASSIC HH-distributor, with fastening option to 07.413.6853.1/0, number of poles 3, rated voltage 250 V, rated current 20 A, number of inputs 1, number of outputs 5, color of coding/ contact carrier black

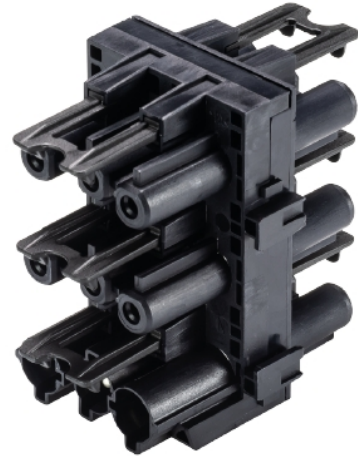

Commercial Art.No.	92.030.0953.1
EAN	4049088391910
Order Unit	1

certificates / approvals



Technical data

general

rated current	20 A
rated voltage	250 V
rated impulse voltage	4 kV
pollution degree	2
mechanical coding	code 1
lockable	self-locking (unlocking by tool)
color of coding/ contact carrier	black
marking of poles	L, N, PE
RAL-number coding/insert connector	9005

model

number of inputs	1
number of outputs	5
type of fastening	yes
degree of protection (IP)	IP40
type of distributor	HH-distributor

material

housing material	polyamide
halogen free	yes
contact material	CuZn
fire load	0.216 kWh/St

insulation components continuous temperature	100 °C
surface finish	tin-plated

dimensions

length	58 mm
width	34.9 mm
height	52.5 mm

classification


ECLASS 11	
ECLASS 8.1	27440603
ETIM 9.0	EC002567
ETIM 8.0	EC002567
ETIM 7.0	EC002567
ETIM 6.0	EC002567
ETIM 5.0	EC002567
ETIM 4.0	EC002567

product compliance

ROHS conformity status	compliant/exempted
ROHS exceptions	III-6(c)
REACH-SVHC conformity status	Duty-To-Declare
REACH-SVHC substances	Lead
REACH-SVHC CAS numbers	7439-92-1

Accessories

Commercial Art.No.:	Article-type description:	Description:
05.561.3653.0	cover cap GST18i3VS B WS	Cover piece for female GST18i3, white
05.561.3653.1	cover cap GST18i3VS B SW	Cover piece for female GST18i3, black
05.564.5353.0	cover cap GST18i3/4/5 SW	Cover piece 12 pole black for female parts GST18i3-6
05.564.5353.2	cover cap GST18i3/4/5 WS	Cover piece 12 pole white for female parts GST18i3-6
05.594.4250.0	cover cap ST18/3B + GST18i3 ST WS	
05.594.4253.0	cover cap ST18/3B + GST18i3 ST WS	
07.413.6853.1	supporting plate GST18 VERTEILER SW	gesis®-Mounting plate for GST18-distributors. For fastening to load-bearing, straight surfaces; fixing on cable trays with moulded expanding rivets; lying distributor mounting; color black

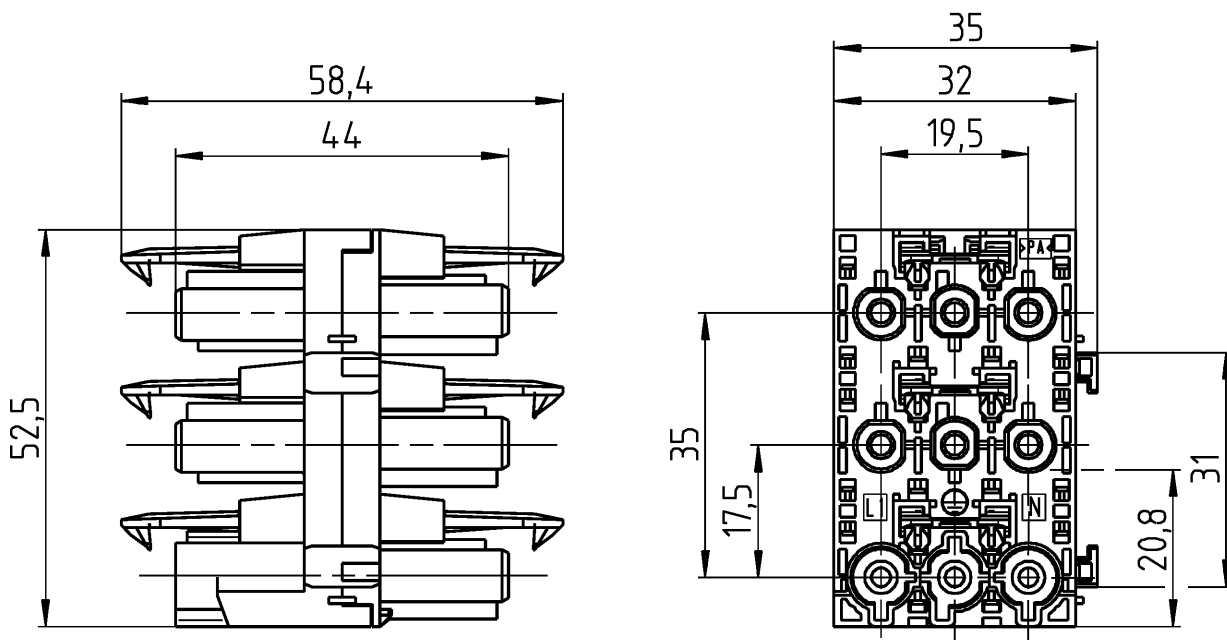

Weitere Daten siehe Katalog
/further data see catalog

Teilenummer /part number	Typ / type	Farbe / colour
92.030.0953.0	GST18I3V 5P1 B V WS	weiß / white
92.030.0953.1	GST18I3V 5P1 B V SW	schwarz / black

Tolerierung Size ISO 14405 / Tolerance system Size ISO 14405 .
(This ISO-standard describes the envelope principle. According to the envelope principle the deviations of form and parallelism are limited by the size tolerances).

ja/yes ☒ Stoffverbots- und Deklarationsliste nach WN 5020.010 ist einzuhalten.
Conformity with Wieland document WN 5020.010 e (list of prohibited /
declarable hazardous substances) to be declared!

Freitoleranz nach General tolerance CAD - Zeichnung, keine manuellen Änderungen CAD - drawing, no manual modifications allowed 1. Verwendung: First Use: Blatt: 1 von 1 Sheet: 1 of 1

Werkstoff / Material		Tag/Date	Name	Zeichnung Nr. / Drawing No.		Index
Maßstab / Scale 1:1		gezeichnet drawn	08.05.2019	Schiller	T 92.030.0953.0 13K	
		geprüft checked				
		Normgepr. Stand. check				
Vol. mm ³ Dfl./Srf. mm ²		Ersatz für / Replacement for:				
wieland www.wieland-electric.com		Type	Bennennung/Title			
Änderung / Revision Datum / Blatt Date / Sheet		siehe Tabelle see table	Verteiler mit Befestigungsmöglichkeit an separater Montageplatte with interface to separate supporting plate			