


Technical data sheet

Article number:

111-03004

T30R

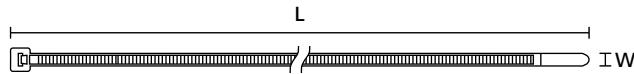

Product Group	Cable Ties Polyamide 6.6 standard
Product Family	T-Series in PA66 coloured
Material	Polyamide 6.6 (PA66)
Colour	Red (RD)

Application Tool	MK3PNSP2, EVOcut, MK7P, MK10-SB, MK20, EVO7, EVO7SP, EVO7i, EVO7iSP
Bundle Ø max.	35.0 mm
Bundle Ø min.	1.5 mm
Flammability	UL 94 V2
Halogen-free	Yes
Length (L)	150 mm
Min.Tensile Strength	135 N
Operating Temperature	-40 °C to +85 °C
Package Content	100 pcs.
Package Content packed in	bag
Releasable Closure (Yes/No)	No
Specifications	IEC 60092 series
Thickness (T)	1.2 mm
Toothing (Serration)	Inside Serrated
UV-Stabilised	No
Variant	Inside Serrated
Weight/Unit	0.0007 kg
Width (W)	3.5 mm

HF ✓ **RoHS** ✓

