

## Features

- Maximum operating pressure is 12 bar.
- Operating temperature range -20°C to +100°C.
- Material: Brass / Steel / Aluminium Nickel & Zinc Plated Finish
- 2-Stage Security
- DN 7.4 Euro Profile
- ISO 4414
- Compatible with:
  - TST 026
  - PARKER - RECTUS 25, 26
  - CEJN 320
  - JWL 520, 530
  - PARKER PEF
  - LEGRIS

## RS PRO Pneumatic Quick Connect Coupling

RS Stock No.: 0325593



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

## Product Description

### RS PRO Series 25S.08 Quick Connect Couplings

Pneumatic quick-connect coupling connectors are found across industry in pneumatic systems as diverse as robotic assembly lines and other equipment.


2 Stage Security System - Security is provided by pressing the button two times or by left-right sleeve twist. First press/twist releases the pressure inside the coupling and the second press/twist ejects the plug for disconnection.

- Maximum operating pressure is 12 bar.
- Operating temperature range -20°C to +100°C.
- Material: Brass / Steel / Aluminium Nickel & Zinc Plated Finish
- 2-Stage Security
- DN 7.4Euro Profile
- ISO 4414
- Compatible with:
  - TST 026
  - PARKER - RECTUS 25, 26
  - CEJN 320
  - JWL 520, 530
  - PARKER PEF
  - LEGRIS


## Specifications

Manufacturer Series	025S.08
Coupling Type	Quick Connect Coupling Socket
Connection Standard	DN 7.4 Euro Profile
Connection Standard Compatible With	TST 026; PARKER - RECTUS 25 & 26; CEJN 320; JWL 520 & 530; PARKER PEF; LEGRIS
Minimum Operating Temperature	-20°C
Maximum Operating Temperature	+100°C
Maximum Operating Pressure	12bar
Flow	2 Stage, ISO 4414
Flow Direction & Sealing	Self-sealing coupling
Material	Aluminium, Brass, Steel
Finish	Nickel Plated
Connection Type	Hose Barb
Thread Size	N/A
Thread Standard	N/A
Thread Gender	N/A
Coupling Gender	Female
Threaded Connection	Female, Male
Seal material	Nitrile Rubber
Hose Barb Connection	8mm

## Specifications

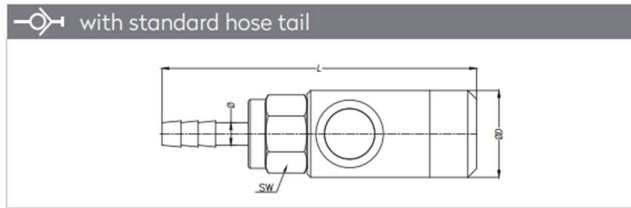

Dimensions (mm)		
SW	L	ØD
20	83.6	26

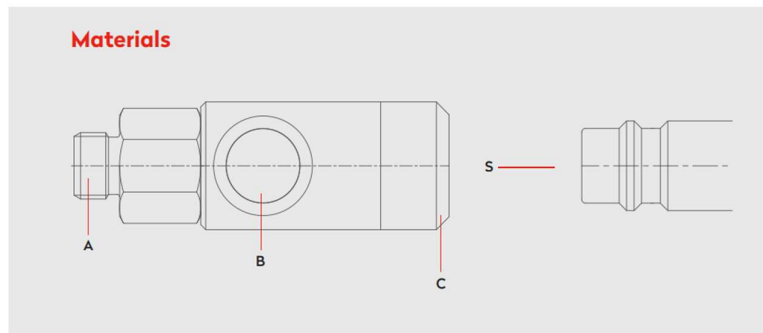



### Material Code

A = Brass Nickel Plated

B = Steel Zinc Plated

C = Aluminium

S = Steel Zinc Plated

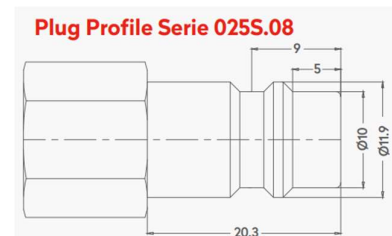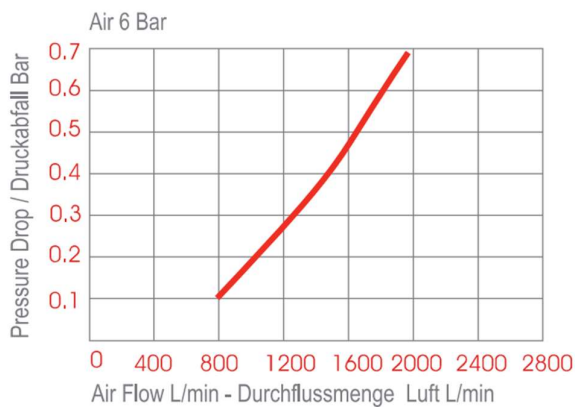

## Series 25S.08 Quick Connect Couplings

	0 - 12 bar (0-174 PSI)		-20° to + 100°C (NBR) -4° to + 212°F	<b>Shut Off Type</b>	
	OM 190 - 00580 OM 178 - 00925 OM 178 - 00975	<b>2 - STAGE</b> <b>ISO 4414</b>		<b>DN</b>	<b>7.4 mm</b>