


Datasheet

3 Way Fused Terminal Block, 16A 300 V, Screw Down, Nylon

RS Stock 452-619

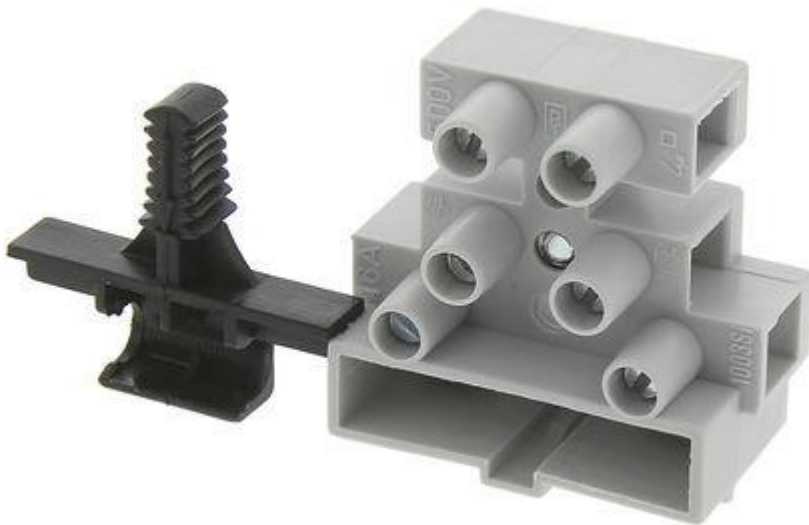

Technical Details

Mouldings:	nylon 6.6, grey, UL94 V2, (fuseholder black)
Inserts:	brass, tinned
Screws:	M3.5 steel, zinc plated, chromed
Screw tightening torque:	max: 0.8 Nm
Temp. limits:	max short term: 160° C continuous: 100° C
Current rating:	to EN 60 127-6: fuseholders: 16A to EN 60 335-1: terminal blocks: 16A to EN 60 598: terminal blocks: 25A to EN 60 998: terminal blocks: 32A
Voltage rating:	terminal blocks: 500v fuseholders: 250v
Conductor size:	without wire protectors: up to 10mm ² with wire protectors: up to 4mm ²
Wire stripping length:	7.5mm ² - 8.0mm ²
Fuse size:	1" x 1/4" or 1.1/4" x 1/4"
Fixing centres:	peg to earth screw: 18mm peg to fixing hole: 24mm

Dimensions: (mm)

