


E40486



Process adapter clamp ISO 2852

ADAPT ISO2852 DN100

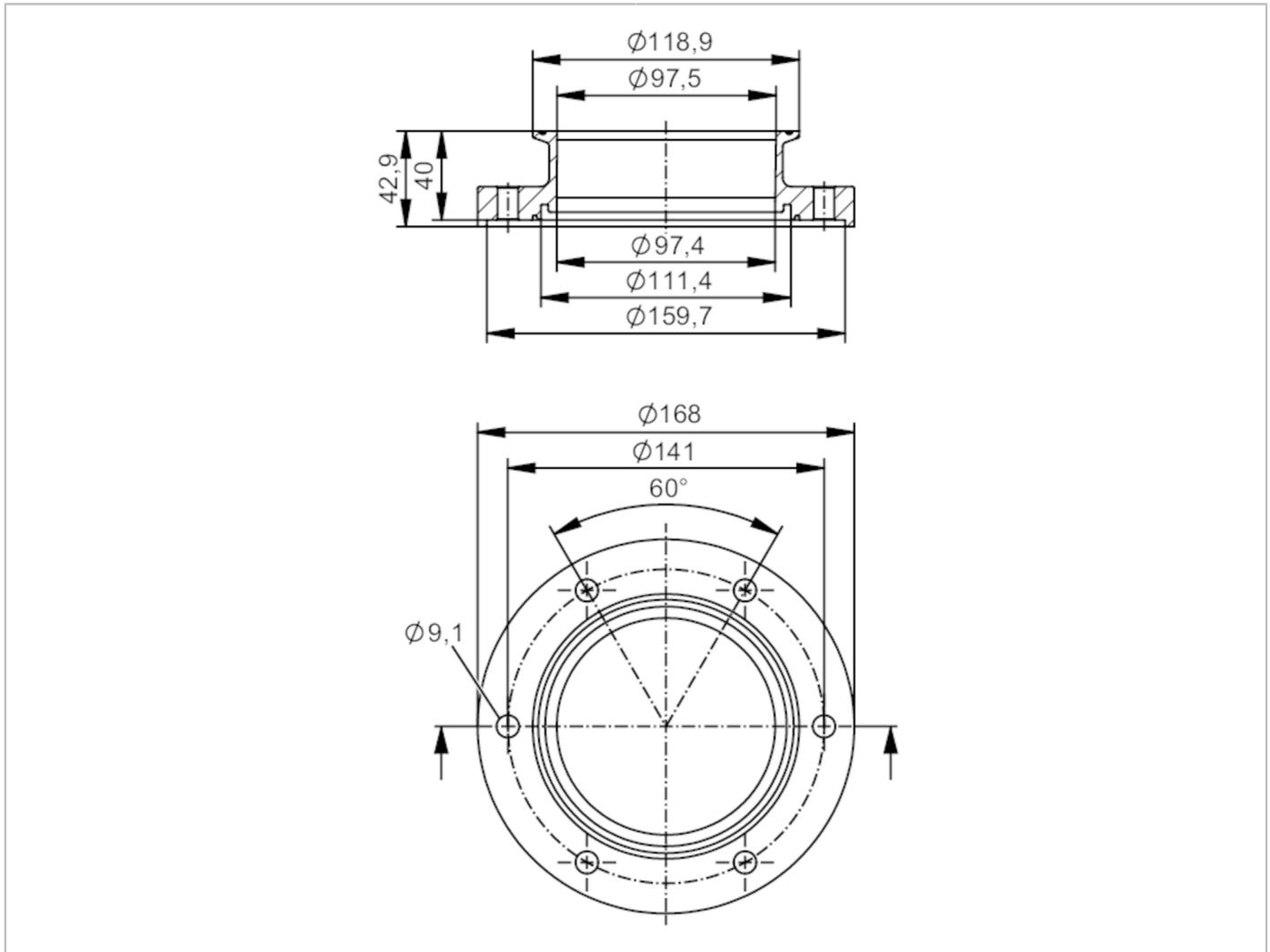

EC 1935/2004 FCM FDA

Application	
Design	for volumetric flow meters SMF
Application	food and beverage industry; hygienic systems
Pressure rating	10 bar 1 MPa
Tests / approvals	
Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.
Mechanical data	
Weight [g]	4990.5
Materials	stainless steel (316L/1.4404)
Nominal diameter	DN100 (4")
Sensor connection	ifm-specific device flange
Process connection	Clamp ISO 2852

E40486



Process adapter clamp ISO 2852

ADAPT ISO2852 DN100

Process connection suitable for pipe standard	(ISO 2037); (DIN EN 10357 Series D); (JIS G3447); (BS 4825 Part 1)
Surface characteristics Ra/Rz of the wetted parts	Ra ≤ 0.4 μm
Accessories	
Items supplied	screws 12
Remarks	
Pack quantity	2 pcs.