




**LED Ecobasic PAR16 Crystal GU10 2.4W (35W) 230lm 827 38°**

Article number: 146263

BAI LED Ecobasic PAR16 Crystal GU10 2.4W (35W) 230lm 2700K 38° 220V-240V 50x53mm MR16 LED reflector lamp

The Bailey Lights LED spotlights are characterized by a longer lifespan and less energy consumption than their halogen predecessors. Due to their compact design they are easily interchangeable. Spots are mainly used to provide focused light from the ceiling or wall. This glass-look version is made of polycarbonate and literally and figuratively has an extra beautiful appearance because the part where the light shines through radiates both to the front and partly to the back. Because these Ecobasic low-budget lamps are very sustainable due to their low power consumption and long lifespan, they are both ECOlogical and ECONomic. Ambient temperature: -20°C to +45°C.

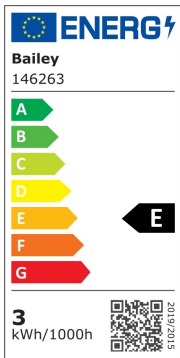

**General ETIM properties**

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED Ecobasic PAR16 Crystal GU10 2.4W (35W) 230lm 827 38°
Brand	Bailey
Productseries	Ecobasic LED spot
Producttype	PAR16 Crystal

## ETIM specifications

Socket	GU10
Luminous flux [lm]	230 - 230
Nominal voltage [V]	220 - 240
Lamp power [W]	2.4 - 2.4
Colour temperature [K]	2700 - 2700
Diameter [mm]	50
Length [mm]	53
Dimmable	No
Lamp shape	Reflector
Beam angle [°]	38 - 38
Colour	White
Type of glass/cover	Clear
Lamp designation	PAR16
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	No
Luminous intensity [cd]	400
Rated luminous flux according to IEC 62612 [lm]	230
Power factor	0.5
Lamp efficacy [lm/W]	96
Nominal current [mA]	24 - 24
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	Colourless
Average nominal lifetime [h]	15000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	15000
Weighted energy consumption in 1000 hours [kWh]	3
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG1
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	No
Dimming phase cut-on (leading edge)	No
Dimming Touch and Dim	No

Dimming Zigbee	No
Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	E
With twilight switch	No
Material of light bulb	Plastic

### Alternative articles



146592


LED Spot PAR16 Brilliant GU10  
DIM 3.8W (35W) 260lm 927 36°



144921


LED Spot PAR16 Glass GU10  
3.5W (35W) 280lm 830 38°

### Complementary articles

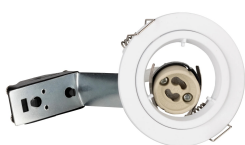

141966

Spot GU10 Set Alu White Fixed

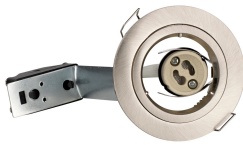

141967

Spot GU10 Set Alu Brushed  
Fixed