


342146-1 Terminals and Splices
Ring and Spade Tongue Terminals

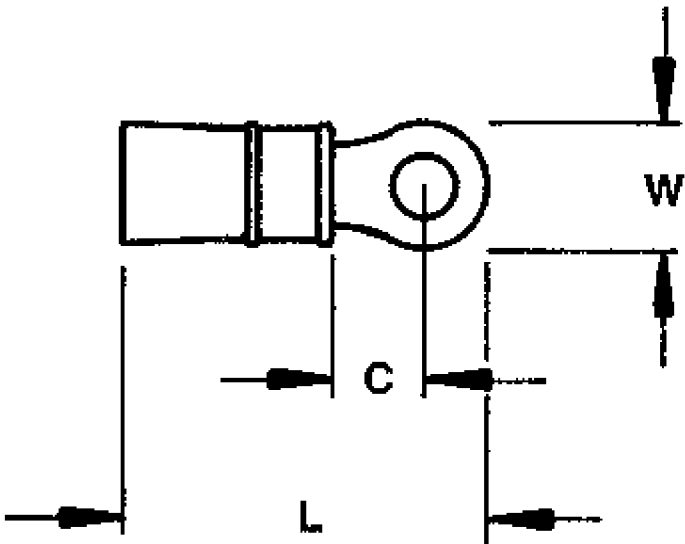

Line art represents typical product only.

Searchable Features:	
Terminal Shape	Ring Tongue
Body Style	PLASTI-GRIP
Receptacle Style	Straight
Barrel Type	Closed Barrel
Wire/Cable Type	Regular Wire
Wire Range	16-14 [1.00-2.60 ²] AWG [mm]
Insulation	Yes
Insulation Support	Non-Insulation Support
Insulation Diameter	.169 [4.30] Max. in. [mm]
Stud Size	5/16 [M8]
Stud Diameter	.327 [8.30] in. [mm]
Shape	RING-043
Heavy Duty	Standard
Packaging Method	Loose Piece
Material	Copper
Finish	Tin
Other Properties:	
Dim. C	.440 [11.10] in. [mm]
Dim. L	1.063 [27.00] in. [mm]
Dim. W	.468 [11.90] in. [mm]
Color	Blue
Insulation Material	Vinyl
Insulation Sleeve Material	PVC
CERTI-CRIMP Hand Tool	47387-7, 525691-0 (Great Britain Tool)