

<b>Universe</b>	Professional
<b>Type</b>	Verticality
<b>Category</b>	Helmets
<b>Subcategory</b>	Lightweight helmets




## STRATO VENT

The STRATO VENT helmet is very lightweight and comfortable, thanks to its CENTERFIT and FLIP&FIT systems, which guarantee that the helmet fits securely on the head. The adjustable-strength chinstrap makes it ideal for both work at height and on the ground. It has ventilation holes that allow airflow through the helmet. With its potential for integration of a Petzl headlamp, hearing protection, and multiple accessories, it is an entirely modular helmet, thus responding to the specific additional needs of professionals.



The liner is designed in two parts, EPP (expanded polypropylene) and EPS (expanded polystyrene) for reduced weight.

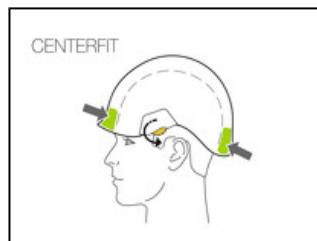

The CENTERFIT feature allows perfect centering of the helmet on the head, thanks to its two side adjustment wheels.



Ventilation holes allow airflow through the helmet.



With its potential for integration of a Petzl headlamp, hearing protection, and multiple accessories, it is an entirely modular helmet, thus responding to the specific additional needs of professionals.

---

**Short Description** Lightweight and ventilated helmet

---

**Selling Points**





- Lightweight and comfortable design:
  - two-part liner, EPP (expanded polypropylene) and EPS (expanded polystyrene) for reduced weight
  - CENTERFIT feature allows perfect centering of the helmet on the head, thanks to its two side adjustment wheels
  - FLIP&FIT system allows the headband to be positioned in a low position, guaranteeing that the helmet fits securely on the head. The system folds into the shell for easy storage and transportation
  - comes with changeable absorbent comfort foam
- Protection designed for work at height and on the ground:
  - DUAL chinstrap allows the worker to adjust chinstrap strength in order to adapt the helmet to different environments: work at height (EN 12492) or on the ground (EN 397). The clip has two positions, corresponding to these two uses: high strength, limiting the risk of losing the helmet during a fall, and low strength, limiting the risk of strangulation if the helmet is snagged while the user is on the ground
  - shock absorption achieved through deformation of the liner
  - ventilation holes allow airflow through the helmet
- Modular accessories:
  - eye shield with EASYCLIP side attachment system for easy installation
  - Petzl headlamp with mounts, or headlamp with elastic headband
  - helmet protector keeps the shell free from soiling and paint splash
  - nape protector provides effective sun and rain protection for the nape of the neck
  - nametag holder allows user to be easily identified
  - changeable chinstrap and foam
  - hearing protection
  - available in four colors: white, yellow, red and black
  - also comes in two high-visibility versions: yellow and orange

---

**Specification**

- Head circumference: 53-63cm
  - Weight: 415g
  - Material(s): ABS (acrylonitrile butadiene styrene), EPP (expanded polypropylene), EPS (expanded polystyrene), nylon, polycarbonate, high-strength polyester, polyethylene
  - Certification(s): CE, EN 12492, ANSI Z89.1 Type I Class C, EAC
-

Specifications by reference

Reference(s)	A020BA00	A020BA01	A020BA02	A020BA03
				
Color(s)	white	yellow	red	black
Made in	FR	FR	FR	FR
Guarantee	3 years	3 years	3 years	3 years
Packing	1	1	1	1
Case quantity	8	8	8	8
EAN	3342540827479	3342540827486	3342540827493	3342540827509