


Trade LED flush emergency bulkhead with sensor



| MLA part code | BT14EMS | BT20EMS |
|--|---------------------------------------|-------------------------------|
| Description | Trade Emergency LED Flush with sensor | |
| Weight (kg) | 1.0 | 1.56 |
| Wattage (W) | 14 | 20 |
| Lumens (lm) | 910 \pm 5% | 1472 \pm 5% |
| Efficacy (lm/W) | 65 | 73 |
| ErP Class | A | |
| Overall dimensions (mm) | Diameter: 315, Projection: 74 | Diameter: 380, Projection: 81 |
| CCT | 4000K | |
| LED Colours | Cool White | |
| Life span (hrs) | 30,000 | |
| Detection range, wall mounted at 1m to 1.8m | 2m to 12m | |
| Detection range, ceiling mounted at 2.5m to 6m | 2m to 6m | |
| Duration | 5sec to 30min | |
| Lux level (lx) | 2 to 50 | |
| Input voltage | Mains 230V 50Hz | |
| Construction | Polycarbonate | |
| Class | Class II double insulated | |
| IP rating | IP44 | |
| Warranty | 3 Years (excluding battery) | |
| Battery type | Ni-Cd 6.0V 2000mAh (5xCell) | |
| Photometric data | Yes | |
| Dimmable | No | |
| Origin of Manufacture | China | |
| Quality assurance system | ISO9001 | |
| Declaration of Conformity (held on file) | Yes | |
| Manufactured & accordance with | BS EN60598-2-22 | |
| EAN | 5055832901594 | 5055832938446 |

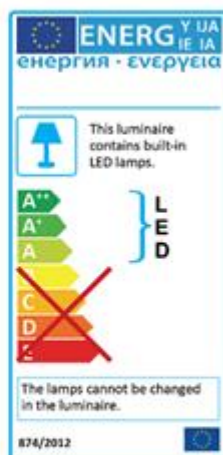