



Identification ties and plates for marking cable bundles

• Arrowtag

Features and Benefits

Where maintenance and repair work is needed, the use of Arrowtags and pre-printed Ovalgrip markers gives the engineer an unlimited variance of text combinations.

Any size of cable diameter can be marked dependant on the length of cable tie chosen. The maximum strap width is 7.4mm.

AT1 will fit 7 size 50 Ovalgrip markers.

AT2 will fit 8 size 85 Ovalgrip markers.

AT3 will fit 14 size 85 Ovalgrip markers.


If needed, the Arrowtags can be written on with T82 marker pens. They can also be direct-printed using the hot stamping process. Just ask us.

Application

Used with Ovalgrip markers for identifying larger pipes and cables.



A clearly better way of identifying cables and pipes.

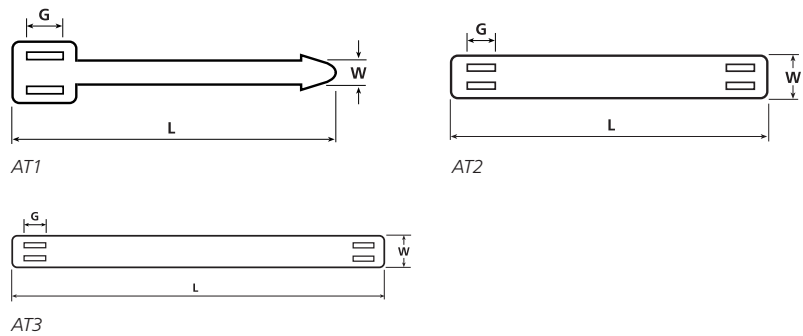

Material Data	
Material	Polyamide 6.6 (PA66)
Colour	Natural (NA), Black (BK)
Operating Temperature	-40 °C to +85 °C Continuous, (+105 °C for 500 h)
Flammability	UL94 V2



Certifications
please see Appendix.

More information on
marker pens can be
found on page 495.

Technical Table

Article-No.	Type	Colour	Length (L)	Width (W)	Strap Width max. (G)	Recommended Ovalgrip Size	Marker tiles per carrier	Pack Cont.
151-41119	AT1	Natural (NA)	62.5	4.70	7.40	50	7	100
151-41110	AT1	Black (BK)	62.5	4.70	7.40	50	7	100
151-41219	AT2	Natural (NA)	63.0	9.00	6.40	85	8	100
151-41210	AT2	Black (BK)	63.0	9.00	6.40	85	8	100
151-41319	AT3	Natural (NA)	100.0	9.00	6.40	85	14	100
151-41310	AT3	Black (BK)	100.0	9.00	6.40	85	14	100

All dimensions in mm. Subject to technical changes.