


1/2" DR. 6PT. DEEP SOCKET (S.A.E.)

PART NO.	SIZE INCH	D1 MM	D2 MM	L MM			G.W. (kg)
13201	3/8"	22.0	14.5	77.0	6	72	12.5
13202	7/16"	22.0	17.0	77.0	6	72	14.2
13203	1/2"	22.0	18.6	77.0	6	72	14.1
13204	9/16"	22.0	20.6	77.0	6	72	14.9
13205	5/8"	22.0	22.0	77.0	6	72	14.3
13206	11/16"	23.8	23.8	77.0	6	72	10.6
13207	3/4"	25.8	25.8	77.0	6	72	12.3
13208	13/16"	27.8	27.8	77.0	4	48	10.0
13209	7/8"	29.8	29.8	77.0	4	48	11.6
13210	15/16"	31.8	31.8	77.0	4	48	13.1
13211	1"	33.8	33.8	77.0	4	60	17.8
13212	1-1/16"	35.8	35.8	77.0	4	60	20.9
13213	1-1/8"	37.8	37.8	77.0	4	60	23.2
13214	1-1/4"	41.8	41.8	77.0	2	24	9.7

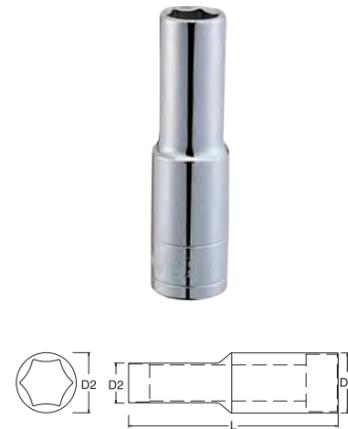

ANSI B107.1

⚠ These sockets should never be used on powers driver and / or extenders.

1/2" DR. 6PT. SOCKET (METRIC)

PART NO.	SIZE MM	D1 MM	D2 MM	L MM			G.W. (kg)
13319	8	22.2	13.3	37.8	6	84	5.5
13320	9	22.2	14.3	37.8	6	84	5.5
13301	10	22.2	15.3	37.8	6	84	5.8
13302	11	22.2	16.5	37.8	6	84	5.8
13303	12	22.2	17.8	37.8	6	84	5.8
13304	13	22.2	19.0	37.8	6	84	5.9
13305	14	22.2	20.3	37.8	6	84	5.9
13306	15	22.2	21.4	37.8	6	84	6.4
13307	16	22.2	22.2	37.8	6	84	6.4
13308	17	23.9	23.9	37.8	6	72	6.3
13309	18	24.9	24.9	37.8	6	72	6.8
13310	19	24.0	25.9	37.8	6	72	6.8
13311	20	24.0	27.8	37.8	4	48	4.9
13312	21	24.0	27.9	37.8	4	48	4.9
13313	22	26.0	29.9	40.0	4	48	5.9
13314	23	26.0	31.1	40.0	4	48	5.9
13315	24	26.0	31.9	40.0	4	48	5.9
13316	27	28.0	35.9	43.0	4	120	19.4
13317	30	31.0	39.9	43.0	2	24	5.6
13318	32	33.0	41.9	43.0	2	24	6.3
13321	34	35.0	43.9	43.0	2	24	7.2



ANSI B107.5M  
DIN 3124

⚠ These sockets should never be used on powers driver and / or extenders.

1/2" DR. 6PT. DEEP SOCKET (METRIC)

PART NO.	SIZE MM	D1 MM	D2 MM	L MM			G.W. (kg)
13401	10	22.0	15.3	77.0	6	72	13.1
13402	11	22.0	16.5	77.0	6	72	13.7
13403	12	22.0	17.8	77.0	6	72	14.2
13404	13	22.0	19.0	77.0	6	72	14.7
13405	14	22.0	20.3	77.0	6	72	15.2
13406	15	22.0	21.4	77.0	6	72	15.9
13407	16	22.0	22.0	77.0	6	72	15.9
13408	17	23.8	23.8	77.0	6	72	10.9
13409	18	24.8	24.8	77.0	6	72	13.5
13410	19	25.8	25.8	77.0	6	72	12.8
13411	20	27.8	27.8	77.0	4	48	10.5
13412	21	27.8	27.8	77.0	4	48	9.7
13413	22	29.8	29.8	77.0	4	48	12.2
13414	24	31.8	31.8	77.0	4	48	13.2
13415	27	35.8	35.8	77.0	4	60	20.5
13416	30	39.8	39.8	77.0	2	24	9.8
13417	32	41.8	41.8	77.0	2	24	10.6



ANSI B107.5M DIN 3124

⚠ These sockets should never be used on powers driver and / or extenders.

1/2" DR. 12PT. SOCKET (S.A.E.)

PART NO.	SIZE INCH	D1 MM	D2 MM	L MM			G.W. (kg)
13501	5/16"	22.2	12.5	37.8	6	84	5.4
13502	3/8"	22.2	14.5	37.8	6	84	5.4
13503	7/16"	22.2	17.5	37.8	6	84	5.8
13504	1/2"	22.2	18.6	37.8	6	84	5.5
13505	9/16"	22.2	20.6	37.8	6	84	5.6
13506	5/8"	22.2	22.2	37.8	6	84	5.8
13507	11/16"	24.2	24.2	37.8	6	72	5.7
13508	3/4"	25.9	25.9	37.8	6	72	6.3
13509	13/16"	27.9	27.9	37.8	4	48	5.3
13510	7/8"	29.9	29.9	37.8	4	48	6.1
13511	15/16"	31.9	31.9	37.8	4	48	6.7
13512	1"	33.9	33.9	40.0	4	120	19.7
13513	1-1/16"	35.9	35.9	40.0	4	120	21.5
13514	1-1/8"	37.9	37.9	42.0	4	120	23.8
13515	1-1/4"	41.9	41.9	42.0	2	24	6.5



ANSI B107.1

⚠ These sockets should never be used on powers driver and / or extenders.

1/2" DR. 12PT. SOCKET (METRIC)

PART NO.	SIZE MM	D1 MM	D2 MM	L MM			G.W. (kg)
13619	8	22.2	13.3	37.8	6	84	5.2
13620	9	22.2	14.3	37.8	6	84	5.4
13601	10	22.2	15.3	37.8	6	84	5.3
13602	11	22.2	16.5	37.8	6	84	5.3
13603	12	22.2	17.8	37.8	6	84	5.3
13604	13	22.2	19.0	37.8	6	84	5.5
13605	14	22.2	20.3	37.8	6	84	5.8
13606	15	22.2	21.4	37.8	6	84	6.2
13607	16	22.2	22.2	37.8	6	84	5.9
13608	17	23.9	23.9	37.8	6	72	6.0
13609	18	24.9	24.9	37.8	6	72	6.4
13610	19	24.0	25.9	37.8	6	72	5.7
13611	20	24.0	27.8	37.8	4	48	4.6
13612	21	24.0	27.9	37.8	4	48	4.4
13613	22	26.0	29.9	40.0	4	48	5.3
13614	23	26.0	31.1	40.0	4	48	5.3
13615	24	26.0	31.9	40.0	4	48	5.3
13616	27	28.0	35.9	43.0	4	48	17.9
13617	30	31.0	39.9	43.0	2	24	5.0
13618	32	33.0	41.9	43.0	2	24	5.5



ANSI B107.5M DIN 3124

⚠ These sockets should never be used on powers driver and / or extenders.