 



suction cup ESS-20-SN

Part number: 189294

FESTO

easily interchangeable,

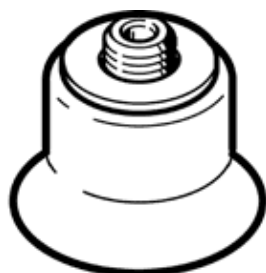

Data sheet

Feature	Value
Min. workpiece radius	60 mm
Nominal size	3 mm
suction cup diameter	20 mm
suction cup volume	0.318 cm ³
Position of connection	on top
Assembly position	Any
Correlation to suction-cup holder	Size 4
Suction cup shape	round flat
Operating pressure	0 ... 0.95 bar
Nominal operating pressure	-0.7 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:::]
Corrosion resistance classification CRC	1 - Low corrosion stress
Food-safe	See Supplementary material information
Ambient temperature	-10 ... 70 °C
Retention force at nominal operating pressure	16.3 N
Lateral force at nominal operating pressure	11.5 N
Product weight	6.4 g
Mounting type	Via vacuum port
Vacuum connection	M6
Colour	Black
Shore hardness	60 +/- 5
Material of threaded plug	Nickel-plated brass Galvanised and chrome-plated steel
Materials note	Free of copper and PTFE Conforms to RoHS
Material suction cup	NBR