

Features

- Easy to install with LCD glass display.
- 3ph voltage and 3ph current transformers
- It shows the current voltage apparent power, frequency
- It shows min-max-ave values, demands
- Modbus RTU remote communication via RS-485
- 1Relay output
- High-low current voltage frequency protection value can be adjusted.
- It shows phase sequence.
- Password protected menu
- Digital multifunction panelmeter

RS PRO Multi-Function Panelmeters

RS Stock No.: 0434505



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

- *Multi-function panelmeters are designed to measure electrical values such as voltage, current, voltage, frequency, apparent power, and min, average, max, demand values of the load or loads in the system to which they are connected.*
- *With remote communication feature of electrical parameters can be monitored and reported independently.*
- *With energy analysers, analyses such as energy quality, efficiency and unit cost calculation can be performed.*
- *Application current voltage frequency apparent power can be monitored.*
- *With relay out, a kind of lad can be controlled.*
- *With menu protected.*

General Specifications

Product type	Multi-function Panel Meter
Function measured	Current, voltage, frequency, apparent power, min max average values,
True RMS	YES
Display type	LCD screen
Operating temperature	-20, +55
Storage temperature	-30, +80
Surge protection	YES
Mounting type	Assembly to panel front cover
Connection type	Terminal

Mechanical Specifications

Width	58 mm
Length	97,5 mm
Height	97,5 mm
Weight	<300 gr

Electrical Specifications

Operating voltage	85-240V AC
Safety Category voltage	CATII
Cable diameter	2,5mm


Protection Category

IP rating	IP41 front panel ,IP20 body
-----------	-----------------------------

Approvals

Compliance/Certifications	CE-UKCA
Hazardous Area Certification	ROHS-3

Wiring Diagram

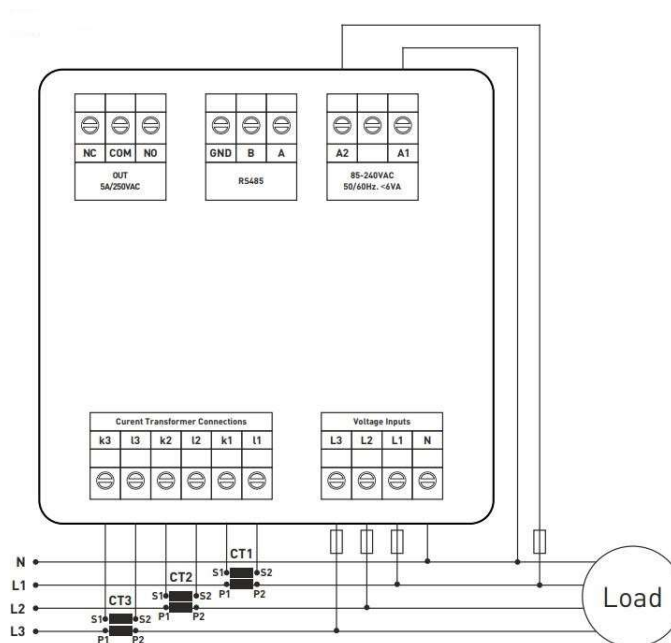

Similar Products

Stock No.	Product Name	Attribute 1	Attribute 2	Attribute 3
0434515	Energy Meter	3phase current transformer	LCD glass screen	It shows current, voltage, power, energy, cos fi, pf, min max average,