

Soft starting device 400 V AC 300-5500W 3PH Overall depth 55 mm



Model		
product brand name	SENTRON	
product designation	Soft-starting device	
design of the product	55 mm	
Supply voltage		
operating voltage rated value		
• minimum	230 V	
• maximum	230 V	
protection class IP	IP20	
Dissipation		
power loss [W]	4.6 W	
power loss [W] for rated value of the current at AC in hot operating state per pole	4.6 W	
Control current		
control supply voltage		
• at AC at 50 Hz rated value minimum	230 V	
• at AC at 50 Hz rated value maximum	230 V	
• at AC at 60 Hz rated value minimum	230 V	
• at AC at 60 Hz rated value maximum	230 V	
Product function		
product function motor overload protection	No	
Mechanical Design		
height	90 mm	
width	105 mm	
depth	55 mm	
net weight	450 g	
Environmental conditions		
ambient temperature without derating rated value	55 °C	
Approvals Certificates		
General Product Approval	other	Environment



[Miscellaneous](#)

[Confirmation](#)

[Environmental Con-
firmations](#)

Environment

[Environmental Con-](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=5TT3440>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/5TT3440>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)



http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=5TT3440

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

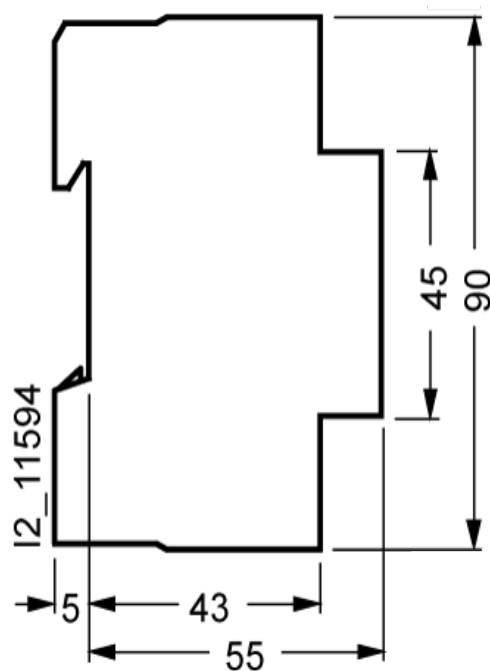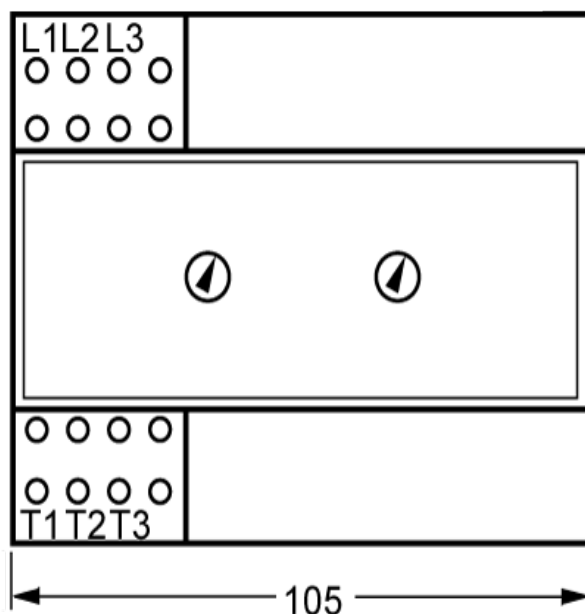

last modified:

4/12/2025

