


FatMax® Xtreme™ Retractable Utility Knife

- Rugged, all-metal construction stands up to the most extreme uses
- Magnetic nose holds blade while it's being changed
- Textured, die-cast finish provides a slip-resistant grip
- Large, clamping dial is easy to operate, even with gloves on
- Dial locks blade firmly in place
- Three-position, retractable blade ensures versatility
- Holds 20 utility blades
- Works with all Stanley® replacement utility blades

Product SKU No.	Handle		Box/Ctn
	Inches	mm	
10-815	7-3/4	197	6 / 36

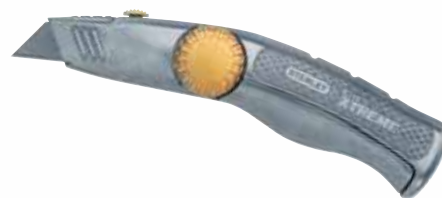

FatMax® Locking Retractable Utility Knife

- Adjustable thumb-dial locking wheel holds blade in place and prevents shifting
- Swivels open for quick blade change – no tools required
- Rear blade storage for seven blades
- Ergonomically designed rubber grip fits comfortably in hand
- Lightweight, durable body

Product SKU No.	Box/Ctn
10-777	6 / 36



SWIVELS OPEN FOR QUICK
BLADE CHANGE,
NO TOOLS REQUIRED.



BLADE ELEVATES
UPON OPENING
FOR QUICK ACCESS.

InstantChange™ Retractable Knife

- Strong, durable construction combines a cast metal core with bi-material soft panels for a sure grip
- Blade changes with the push of a button – no tools required
- Curved handle design for comfort, control and balance
- Swing-out blade storage for easy blade access
- Integrated string cutter and retractable slide
- Large hang hole for pegboard storage
- Padded thumb rest

Product SKU No.	Handle		Box/Ctn
	Inches	mm	
10-788	6-1/2	165	6 / 36



ALL STANLEY UTILITY KNIVES FEATURE A PATENTED INTERLOCKING NOSE WHICH JOINS OVERLAPPING KNIFE HALVES TO SECURE BLADE, PROVIDING KNIFE STABILITY.