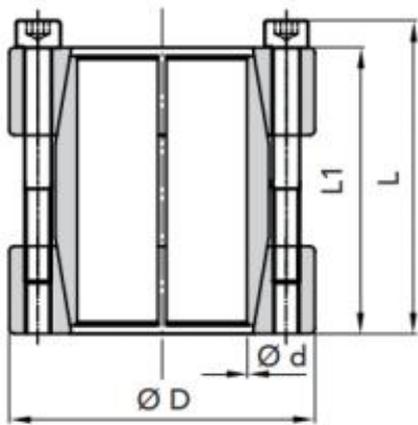


06950025

RCK 95 - Rigid joint

2D Technical Drawing

Dynamic 3D View
Technical Specifications

Part number (CODE)	06950025
Ød (DD) mm	25
ØD (D) mm	55
L1 (L1) mm	60
L (L) mm	66
Maximum torque Mt (MT) Nm	450
Clamping pressure - Shaft (CPS) N/mm ²	110
Clamping screws DIN 912 MAT. 12.9 - Num. (CSN)	6
Clamping screws DIN 912 MAT. 12.9 - Type (CST)	M6x50
Clamping screws DIN 912 MAT. 12.9 - Torque (CSTQ) Nm	17
Weight (WEIGHT) kg	0.69