


Geberit Mapress Carbon Steel T-piece with female thread (FKM, blue)



Example image

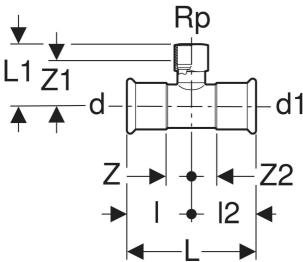

APPLICATION PURPOSES

- For district heating water $\leq 140\text{ }^{\circ}\text{C}$
- For thermal media (solar)
- For mineral and lubricating oil
- For motor fuels (e.g. diesel)
- For compressed air (oil purity class 3–4)

- For solar technology, industry and shipbuilding

- Pressing socket with black protection plug

CHARACTERISTICS

- Pressing indicator
- Outside zinc-plated
- Seal ring made of FKM, blue

TECHNICAL DATA

Product material	Non-alloy steel 1.0034 E195 (EN 10305)
------------------	--

Art. no.	DN	d, ø mm	Rp "	d1, ø mm	arc °	L cm	L1 cm	I cm	I2 cm	Z cm	Z1 cm	Z2 cm
51413	12 / 15 / 12	15	1/2	15	90	6.4	3.7	3.2	3.2	1.2	2.4	1.2
51414	15	18	1/2	18	90	6.8	3.9	3.4	3.4	1.4	2.6	1.4
51416	20 / 15 / 20	22	1/2	22	90	7.4	4	3.7	3.7	1.6	2.7	1.6
51417	20 / 20 / 20	22	3/4	22	90	7.4	4.4	3.7	3.7	1.6	2.8	1.6
51418	25 / 15 / 25	28	1/2	28	90	8.4	4.4	4.2	4.2	1.9	3.1	1.9

Art. no.	DN	d, ø mm	Rp "	d1, ø mm	arc °	L cm	L1 cm	I cm	I2 cm	Z cm	Z1 cm	Z2 cm
51419	25 / 20 / 25	28	3/4	28	90	8.4	4.7	4.2	4.2	1.9	3.2	1.9
51421	32 / 15 / 32	35	1/2	35	90	10	4.8	5	5	2.4	3.5	2.4
51422	32 / 20 / 32	35	3/4	35	90	10	5.1	5	5	2.4	3.6	2.4
51424	40 / 15 / 40	42	1/2	42	90	11.4	5.1	5.7	5.7	2.7	3.8	2.7
51425	40 / 20 / 40	42	3/4	42	90	11.4	5.4	5.7	5.7	2.7	3.9	2.7
51427	50 / 15 / 50	54	1/2	54	90	13.8	5.7	6.9	6.9	3.4	4.4	3.4
51428	50 / 20 / 50	54	3/4	54	90	13.8	6	6.9	6.9	3.4	4.5	3.4
51429	50	54	2	54	90	13.8	7.9	6.9	6.9	3.4	5.6	3.4
51437	65 / 20 / 65	76.1	3/4	76.1	90	23	7.4	11.5	11.5	6.2	5.9	6.2
51438	65 / 50 / 65	76.1	2	76.1	90	23	9.1	11.5	11.5	6.2	6.8	6.2
51440	80 / 20 / 80	88.9	3/4	88.9	90	26	8	13	13	7	6.5	7
51441	80 / 50 / 80	88.9	2	88.9	90	26	9.7	13	13	7	7.4	7
51443	100 / 20 / 100	108	3/4	108	90	31	9	15.5	15.5	8	7.5	8