



Datasheet

Stock No: 146-8981

ENGLISH

## RS Pro LED Emergency Exit Sign



### Features:


- Easy to install - Plug and play, maintained and non-maintained in one
- 3 year warranty
- Affordable range

### Specifications:

Input voltage:	220 - 240 Vac, 50 Hz
Lamp type:	2 x 0.5W LED (= 1W LED)
Power consumption:	(VA/W) 5/2
Operation duration (hrs):	3
Environment temperature (°C):	0 to +40
Weight (kg):	0.6

Configurable pictograms included



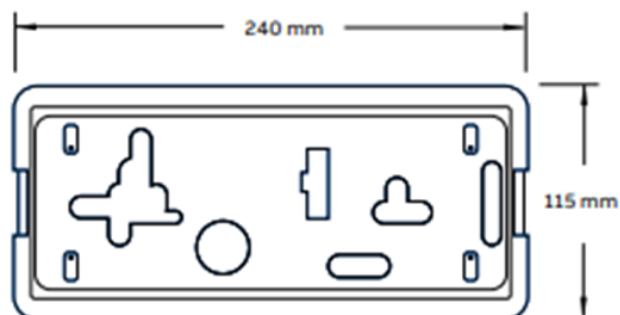

Spacing table

Mounting height (m)	┌─┐	┐─┐	┐─┐	┐─┐	┐─┐
2.00	2.49	6.57	6.92	7.19	2.57
2.50	2.50	6.93	7.17	7.34	2.56
3.00	2.39	7.11	7.28	7.40	2.43
3.50	2.14	7.12	7.22	7.32	2.17
4.00	1.68	6.96	6.99	7.07	1.72