

Han A Hood Coupler 1 Lever M20

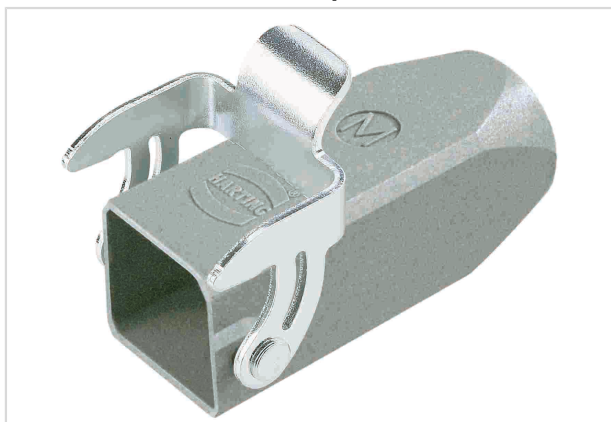


Image is for illustration purposes only. Please refer to product description.

Part number	19 20 003 1750
Specification	Han A Hood Coupler 1 Lever M20
HARTING eCatalogue	https://b2b.harting.com/19200031750

Identification

Category	Hoods/Housings
Series of hoods/housings	Han A [®]
Type of hood/housing	Cable to cable housing

Version

Locking type	Single locking lever
Size	3 A
Version	Top entry
Cable entry	1x M20
Field of application	Standard Hoods/housings for industrial applications

Technical characteristics

Limiting temperature	-40 ... +125 °C
Degree of protection acc. to IEC 60529	IP44 IP65 / IP67 with seal screw 09 20 000 9918
Type rating acc. to UL 50 / UL 50E	12

Material properties

Material (hood/housing)	Zinc die-cast
Surface (hood/housing)	Powder-coated
Colour (hood/housing)	RAL 7037 (dust grey)
Material (locking)	Steel
Surface (locking)	Zinc plated



Pushing Performance

Material properties

RoHS	compliant with exemption
RoHS exemptions	6(a) / 6(a)-I: Lead as an alloying element in steel for machining purposes and in galvanised steel containing up to 0,35 % lead by weight / Lead as an alloying element in steel for machining purposes containing up to 0,35 % lead by weight and in batch hot dip galvanised steel components containing up to 0,2 % lead by weight
ELV status	compliant with exemption
China RoHS	50
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	Yes
REACH SVHC substances	Lead

Specifications and approvals

Approvals	DNV GL
CE	Yes

Commercial data

Packaging size	10
Net weight	71.15 g
Country of origin	Germany
European customs tariff number	85389099
eCl@ss	27440202 Shell for industrial connectors