

Sub-base VABS-S7-S-G14

FESTO

Festo SE & Co. KG

Rüter Straße 82
73734 Esslingen
Germany
+49 711 347-0
www.festo.com

1. Further applicable documents

 All available documents on the product → www.festo.com/pk


2. Safety

- Switch off compressed air before mounting work.


3. Intended use

Connector between a solenoid valve VOFC/VOFD with a NAMUR port pattern according to VDI/VDE 3845 Part 1:2010-09 and a NAMUR rib or NAMUR column for lift drives.


4. Scope of delivery

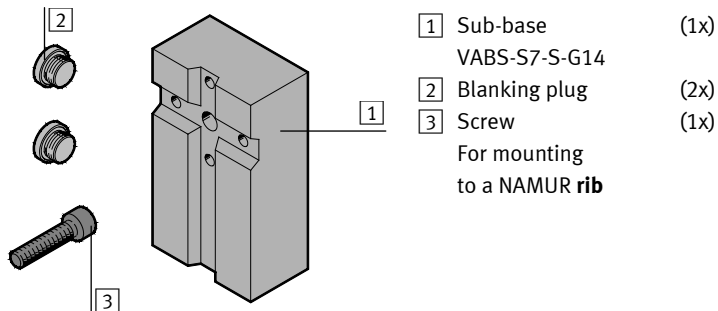


5. Not in scope of delivery

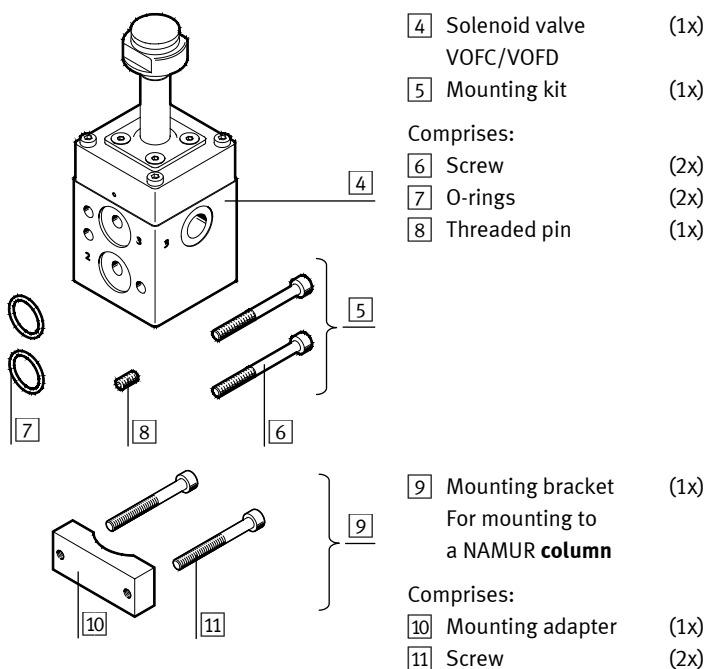


6. Mounting

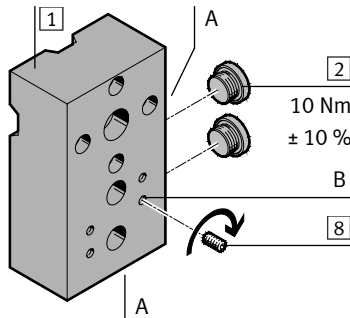


- Screw both blanking plugs [2] into the thread (A). Observe the tightening torque.
- Screw the threaded pin [8] into the thread (B).

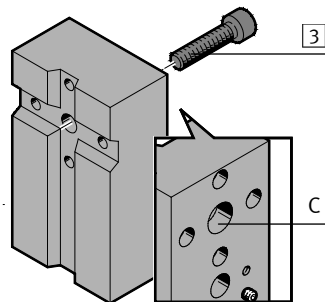

- For mounting to a NAMUR rib
- Push the screw [3] through the drill hole (C).

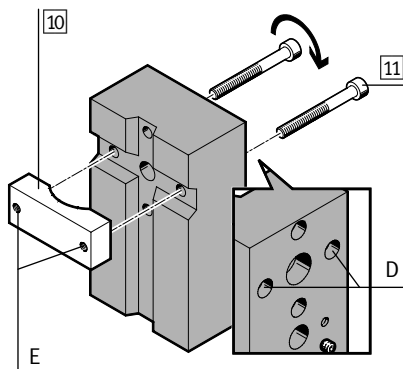


- For mounting to a NAMUR column (alternative)
- Push the screws [11] through the drill holes (D).
 - Screw the screws into the thread (E) of the mounting adapter [10].

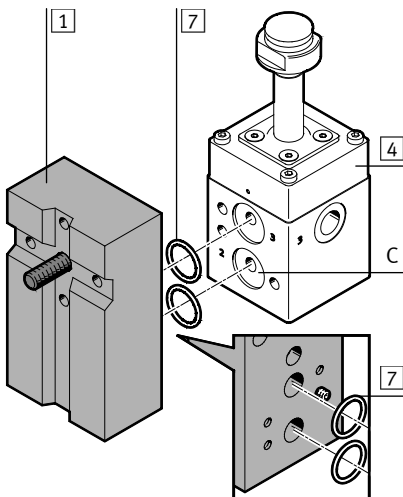

i Information
The solenoid valve [4] can also be mounted rotated downwards by 180°.

- Press O-rings [7] into the depressions (C) of the solenoid valve [4].
- Place the solenoid valve [4] on the sub-base [1].

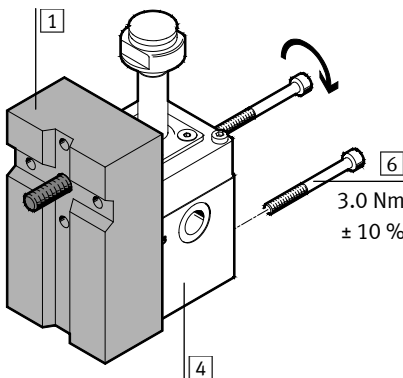

- Tighten screws [6]. Observe the tightening torque.